

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300100877

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change A-Size Double-Ended Cordset, 4 Poles, Male (Straight) to Female (Straight), 16 AWG, TPE Cable, 15.0m (49.21') Length

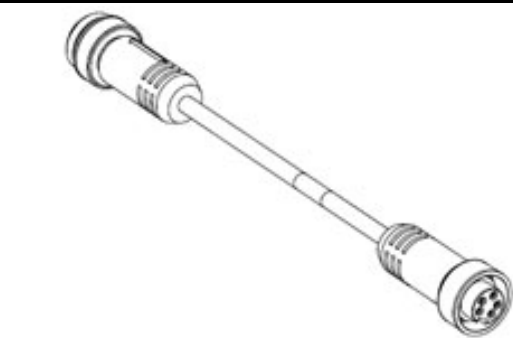

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E152210
General	
Product Family	Industrial Cordsets
Series	130010
Connector End A	Mini-Change
Connector End B	Mini-Change
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Protocol	DeviceNet
Region	America
Type	Double Ended
UPC	78678883486
Physical	
Cable Diameter	10.67mm (.420")
Cable Length	15.0m (49.21')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Female-Male
Keyway	Single
LED Indicator	No
Material - Cable Jacket	TPE
Material - Connector Body	TPE
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - Plating Mating	Gold
Net Weight	2614.000/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	16
Wire/Cable Type	TC-ER
Electrical	
Current - Maximum per Contact	10.0A
Voltage - Maximum	600V
Material Info	
Engineering Number	114030K12M150
Reference - Drawing Numbers	
Sales Drawing	SD-130010-016-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

130010 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[130010-0877](#)