

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300130193

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change A-Size Receptacle, 3 Poles, 1/2"- 14 NPT Threads, Male (Straight) to 18 AWG Leads, 0.305m (1.0') Length

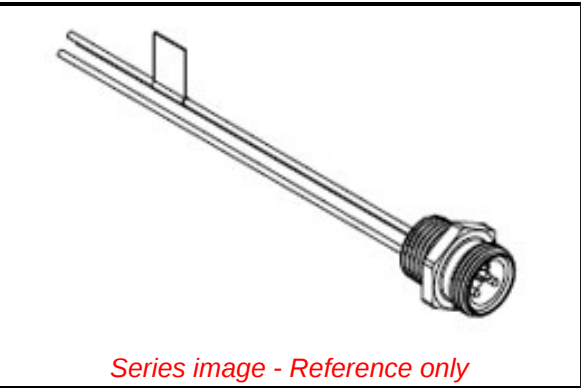

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Receptacles
Series	130013
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Type	Single Ended (pigtail)
UPC	78678844925
Physical	
Coupling Type	External Thread
Gender	Male
Keyway	Single
Length	0.305m
Material - Component	Zinc Die-Cast with Black Epoxy
Mounting Thread Size	1/2" - 14 NPT
Net Weight	38.680/g
Orientation	Straight
Panel Mount	Front
Poles	3
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	18
Wire/Cable Type	UL 1061
Electrical	
Current - Maximum per Contact	10.0A
Voltage - Maximum	300V AC/DC
Material Info	
Engineering Number	1R3006A17A120
Reference - Drawing Numbers	
Sales Drawing	SD-130013-077-001

EU ELV Not Relevant	
EU RoHS Compliant with Exemption 6(c) REACH SVHC Contained Per - D(2020)9139-DC (19 Jan 2021) Lead Halogen-Free Status Not Low-Halogen For more information, please visit Contact US	China RoHS
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

130013 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300130193