

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300130215

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change A-Size Receptacle with Leads, 1/2" - 14 NPT Threads, Male (Straight) 3 Poles, 1.83m (6.0') Length

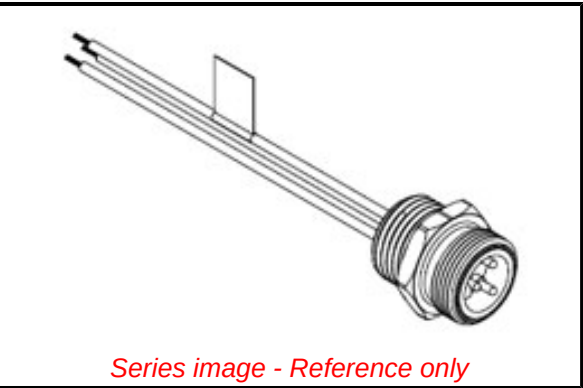

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Receptacles
Series	130013
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Type	Single Ended (pigtail)
UPC	78678843906
Physical	
Coupling Type	External Thread
Gender	Male
Keyway	Single
Length	1.83m
Material - Component	Zinc Die-Cast with Black Epoxy
Mounting Thread Size	1/2" - 14 NPT
Net Weight	99.000/g
Orientation	Straight
Panel Mount	Front
Poles	3
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	16
Wire/Cable Type	UL 1015
Electrical	
Current - Maximum per Contact	13.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	1R3006A20F060
Reference - Drawing Numbers	
Sales Drawing	1300130004-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

130013 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300130215](#)