

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 1300130301

Status: **Active**

Overview: Brad Mini-Change Connectors

Description: Mini-Change A-Size Receptacle, 4 Poles, 1/2" - 14 NPT Threads, Female (Straight) to 16 AWG, 2.0m (6.56') Length

Documents:

Drawing (PDF)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	LR6837
UL	E152210

General

Product Family	Industrial Receptacles
Series	<u>130013</u>
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	<u>Brad Mini-Change Connectors</u>
Product Name	Mini-Change
Type	Single Ended (pigtail)
UPC	78678850257

Physical

Coupling Type	Internal Thread
Gender	Female
Keyway	Single
Length	2.0m
Material - Component	Nickel-plated Zinc Die-Cast
Mounting Thread Size	1/2" - 14 NPT
Net Weight	219.171/g
Orientation	Straight
Panel Mount	Front
Poles	4
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	16
Wire/Cable Type	UL 1015

Electrical


Current - Maximum per Contact	8.0A
Voltage - Maximum	600V AC/DC

Material Info

Engineering Number 1R4000A39M020

Reference - Drawing Numbers

Sales Drawing SD-130013-086-001

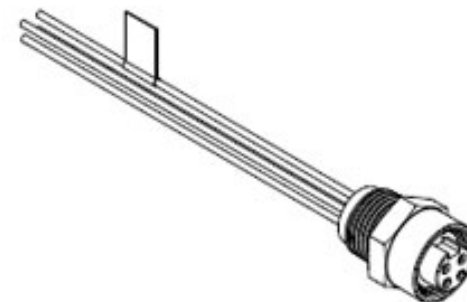

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

130013 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300130301