

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300130403](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change Receptacle, 4 Poles, Stainless Steel Flange Mount, Female (Straight) to 16 AWG Leads, 1.83m (6.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
UL E152210

General

Product Family Industrial Receptacles
Series [130013](#)
IP Rating IP67
NEMA Rating NEMA 6
Overview [Brad Mini-Change Connectors](#)
Product Name Mini-Change
Type Single Ended (pigtail)
UPC 78678844490

Physical

Coupling Type External Thread
Gender Female
Keyway Single
Length 0.30m
Material - Component PVC
Mounting Thread Size N/A
Orientation Straight
Panel Mount With Flange
Poles 4
Temperature Range - Operating -20° to +105°C
Wire Size AWG 16
Wire/Cable Type UL 1015

Electrical


Current - Maximum per Contact 10.0A
Voltage - Maximum 600V

Material Info

Engineering Number 1R4G04A20A1201

Reference - Drawing Numbers

Sales Drawing SD-130013-009-001

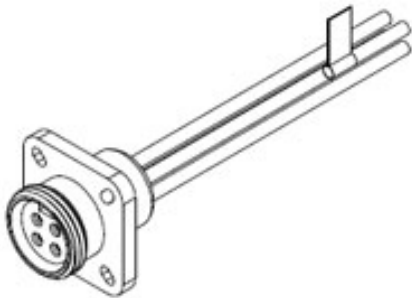

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130013](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300130403