

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300130614

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change A-Size Receptacle, 6 Poles, Female (Straight) to 16 AWG Leads, 0.305m (1.0') Length with Mounting Flange

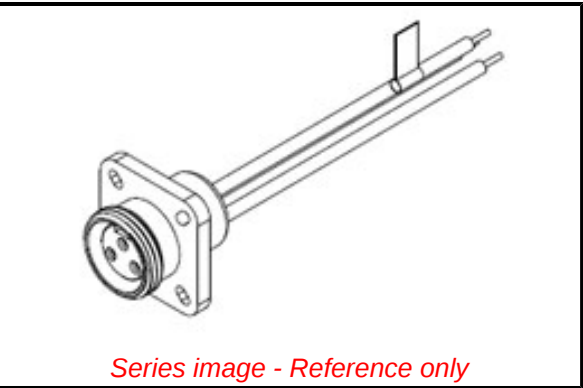

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
CSA		LR6837
UL		E152210
General		
Product Family		Industrial Receptacles
Series		130013
IP Rating		IP67
NEMA Rating		NEMA 6
Overview		Brad Mini-Change Connectors
Product Name		Mini-Change
Type		Single Ended (pigtail)
UPC		78678843954
Physical		
Coupling Type		External Thread
Gender		Female
Keyway		Single
Length		0.305m
Material - Component		Gray Anodized Aluminum
Mounting Thread Size		N/A
Orientation		Straight
Panel Mount		Front
Poles		6
Temperature Range - Operating		-20° to +105°C
Wire Size AWG		16
Wire/Cable Type		E152210
Electrical		
Current - Maximum per Contact		8.0A
Voltage - Maximum		600V AC/DC
Material Info		
Engineering Number		1R6G04A20A120
Reference - Drawing Numbers		
Sales Drawing		SD-130013-021-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130013 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300130614