

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300150140

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change C-Size Receptacle, 9 Poles, 1/2" - 14 NPT Threads, Male (Straight) to Leads, 0.91m (3.0') Length

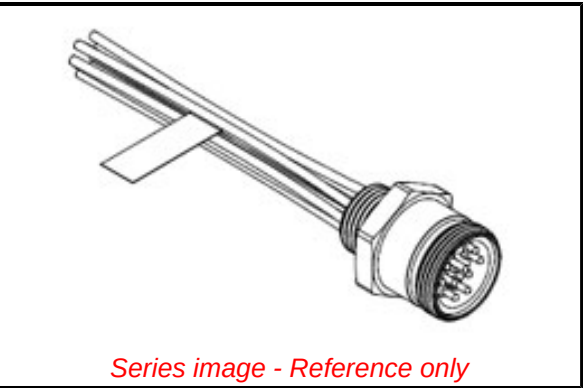

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Receptacles
Series	130015
Comments	C-Size (1-1/8" - 16 UN-2A)
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Type	Single Ended (pigtail)
UPC	78678844211
Physical	
Coupling Type	External Thread
Gender	Male
Keyway	Single
Length	0.91m
Material - Component	Zinc Die-Cast with Black Epoxy
Mounting Thread Size	1/2" - 14 NPT
Orientation	Straight
Panel Mount	N/A
Poles	9
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	16
Wire/Cable Type	N/A
Electrical	
Current - Maximum per Contact	7.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	3R9006A20F030
Reference - Drawing Numbers	
Sales Drawing	SD-130015-003-001, SD-130015-027-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130015 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300150140