

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300238015](#)
Status: **Active**
Description: Brad M16 Single-Ended Cordset, 14 Poles, 6 Ports, Female (Straight) to Pigtail, 0.75mm²/0.34mm² (19/22 AWG), WSOR Cable, 15.0m (49.21')

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	130023
Connector End A	M16
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Product Name	Brad M16
Protocol	N/A
Type	Single Ended
UPC	889056141413

Physical

Cable Diameter	8.00mm (.315")
Cable Length	15.0m (49.21')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	TPU
Material - Connector Body	PUR
Material - Coupling Nut	Brass
Material - Plating Mating	Gold
Orientation	Straight to Pigtail
Poles	14
Temperature Range - Operating	-25°C to +80°C
Wire Size AWG	19, 22
Wire/Cable Type	WSOR

Electrical


Current - Maximum per Contact	3.0A
Voltage - Maximum	60V AC

Material Info

Engineering Number	L04200B78M150
--------------------	---------------

Reference - Drawing Numbers

Sales Drawing	1300238013-000
---------------	----------------

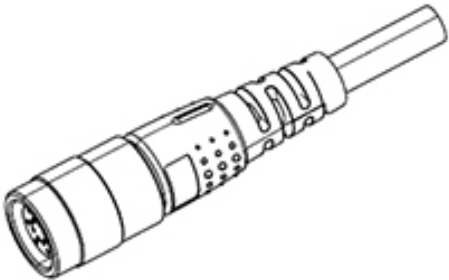

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130023](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300238015