

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300390382](#)
Status: **Active**
Overview: [Brad Micro-Change \(M12\) Connectors](#)
Description: Micro-Change Terminator, Male Standard with Resistor, 5 Pole

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Field Attachable / Accessories
Series [130039](#)
IP Rating IP67
Material - Contact Copper Alloy
Overview [Brad Micro-Change \(M12\) Connectors](#)
Product Name Micro-Change (M12)
Type Terminator
UPC 78172553456

Physical
Cable Diameter N/A
Coupling Type External Thread
Diagnostics / LEDs No
Diagnostics Port No
Gender Male
Keyway Single
Material - Connector Body Polyamide
Material - Coupling Nut Black Epoxy Coated Zinc
Material - Plating Mating Gold
Net Weight 98.000/g
Orientation Straight
Poles 5
Temperature Range - Operating 0°C to +60°C
Wire Size AWG N/A

Electrical
Current - Maximum per Contact 4.0A
Voltage - Maximum 30V

Material Info
Engineering Number DND100

Reference - Drawing Numbers
Sales Drawing SD-130039-011-001

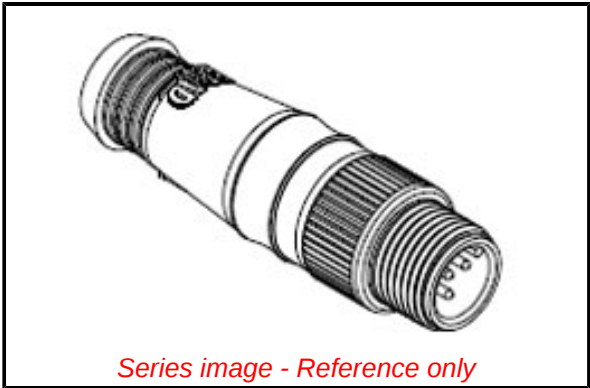

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
Lead	
Halogen-Free Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[130039](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[130039-0382](#)