


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300550001](#)
Status: **Active**
Overview: [Brad Industrial Ethernet Solutions](#)
Description: Brad RJ-Lnxx Ethernet Pass-Through RJ-45 Female Receptacle Shielded

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Industrial Receptacles
Series	130055
IP Rating	IP67
Overview	Brad Industrial Ethernet Solutions
Product Name	Brad, RJ-Lnxx, RJ45
Type	Bulkhead Feed-Through
UPC	78172553725
Physical	
Coupling Type	External Thread
Gender	Female
Keyway	None
Length	N/A
Material - Component	ABS
Mounting Thread Size	1" - 14 UNC
Net Weight	27.100/g
Orientation	Straight
Panel Mount	N/A
Poles	N/A
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	N/A
Wire/Cable Type	N/A
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	125V DC
Material Info	
Engineering Number	ENSP1F5
Reference - Drawing Numbers	
Sales Drawing	SD-130055-017-001

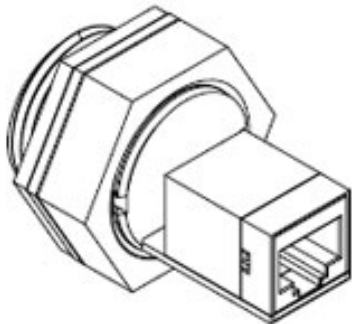

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2020)9139-DC (19 Jan 2021) Halogen-Free Status Not Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[130055 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[130055-0001](#)