

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300660078](#)
Status: **Active**
Overview: [BradPower Cordsets and Receptacles](#)
Description: BradPower A-Size (7/8"–M22) Receptacle, 4 Poles, Male, 1/2" - 14 NPT, 16/1 AWG, 0.5m (19.7") Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Receptacles
Series [130066](#)
IP Rating IP67
Overview [BradPower Cordsets and Receptacles](#)
Product Name BradPower A-Size
Type Single Ended (pigtail)
UPC 78678804268

Physical


Coupling Type External Thread
Gender Male
Keyway Single
Length 0.50m
Material - Component Zinc Die-Cast with Black Epoxy
Mounting Thread Size 1/2" - 14 NPT
Orientation Straight
Panel Mount Front
Poles 4
Temperature Range - Operating -20° to +90°C
Wire Size AWG 16
Wire/Cable Type THHN

Electrical

Current - Maximum per Contact 10.0A
Voltage - Maximum 600V

Material Info

Engineering Number 1R4006A20M005G

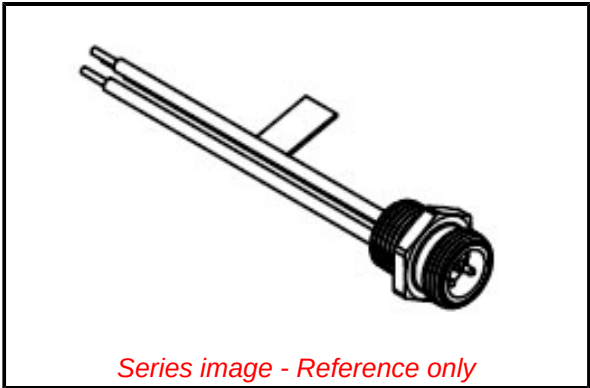

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130066](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

130066-0078