

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300660160](#)
Status: **Active**
Overview: [BradPower Cordsets and Receptacles](#)
Description: BradPower D-Size (1 3/8"–M35) Female, 1/2" NPT 2, 4 Poles, Receptacle, Female (Straight) to 10 AWG Leads, 2.0m (6.56') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Receptacles
Series [130066](#)
IP Rating IP67
Overview [BradPower Cordsets and Receptacles](#)
Product Name BradPower D-Size
Type Single Ended (pigtail)
UPC 78678880934

Physical

Coupling Type Internal Thread
Gender Female
Keyway Single
Length 2.0m
Material - Component Black Anodized Aluminum
Mounting Thread Size 1/2" NPT
Orientation Straight
Panel Mount Back, Front
Poles 4
Temperature Range - Operating -20° to +105°C
Wire Size AWG 10
Wire/Cable Type THHN

Electrical


Current - Maximum per Contact 25.0A
Voltage - Maximum 600V

Material Info

Engineering Number CR4000A30M020

Reference - Drawing Numbers

Sales Drawing SD-130066-025-001

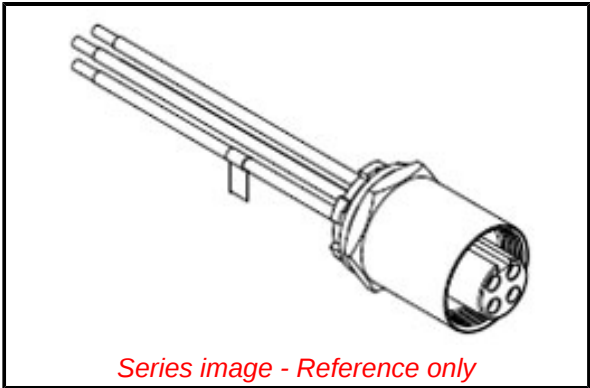

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130066](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300660160