


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300680082](#)
Status: **Active**
Overview: [BradPower Cordsets and Receptacles](#)
Description: BradPower D-Size (1 3/8"–M35) 4-Pole Reducing Tee, with 4-Pole BradPower A-Size (7/8"–M22) Drop, Alternate Keyway Drop, Black

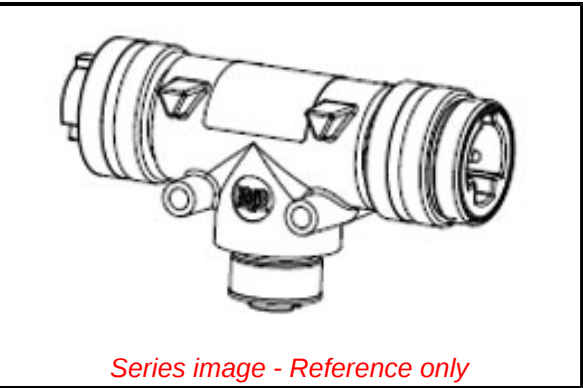

Series image - Reference only

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
UL	E258922
General	
Product Family	Industrial Tees and Splitters
Series	130068
IP Rating	IP67
Overview	BradPower Cordsets and Receptacles
Product Name	BradPower D-Size
Type	Power Tap Tee
UPC	78678877141
Physical	
Drop Connector	BradPowerA-Size (7/8"–M22)
Drop Gender	Female
Keyway	Alternate
Left Trunk Connector	BradPower D-Size (1 3/8"–M35)
Left Trunk Gender	Female
Leg 1 Length	N/A
Leg 2 Length	N/A
Material - Cable Jacket	N/A
Material - Connector Body	PVC
Material - Coupling Nut	Anodized Aluminum
Poles	4
Right Trunk Connector	BradPower D-Size (1 3/8"–M35)
Right Trunk Gender	Male
Temperature Range - Operating	-20°C to +90°C
Electrical	
Current - Maximum per Contact	15.0A, 25.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	TC41140-200
Reference - Drawing Numbers	
Sales Drawing	SD-130068-011

EU ELV Not Reviewed	
EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[130068](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300680082