

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300940007

Status:


Active

Overview:

Support Grips

Description:

Standard Duty Support Grip, Double "U" Eye, Split Rod, Single Weave, Cable Diameter 88.90-101.35m (3.500-3.990"), Approximate Break Strength 2394.97kg (5280 lbs), Stainless Steel

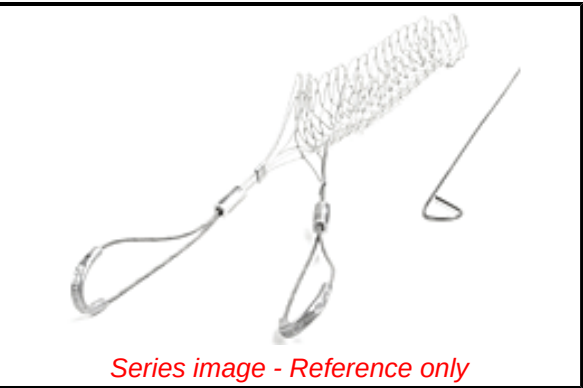

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

|                             |                               |
|-----------------------------|-------------------------------|
| General                     |                               |
| Product Family              | Cable Grips                   |
| Series                      | 130094                        |
| Eye Type                    | Double                        |
| NEMA Rating                 | NEMA 4                        |
| O-Ring                      | No                            |
| Overview                    | Support Grips                 |
| Product Name                | Standard Duty                 |
| Type                        | Support Grip                  |
| UPC                         | 78678899699                   |
| Physical                    |                               |
| Approximate Break Strength  | 2394.97kg (5280 lbs)          |
| Bale Length                 | 0.203m (8.00")                |
| Body Style                  | Straight                      |
| Cable Diameter              | 88.90-101.35mm (3.500-3.990") |
| Color - Grommet             | N/A                           |
| Gender                      | N/A                           |
| Material - Body             | N/A                           |
| Material - Grip             | Stainless Steel               |
| Mesh Length                 | 0.711m (28.00")               |
| Number of Holes             | N/A                           |
| Thread Size                 | N/A                           |
| Material Info               |                               |
| Engineering Number          | 35280SS                       |
| Reference - Drawing Numbers |                               |
| Sales Drawing               | SD-130094-044                 |

|                                                               |              |
|---------------------------------------------------------------|--------------|
| EU ELV                                                        |              |
| Not Reviewed                                                  |              |
| EU RoHS                                                       | China RoHS   |
| Not Reviewed                                                  |              |
| REACH SVHC                                                    |              |
| Not Reviewed                                                  |              |
| Halogen-Free                                                  |              |
| Status                                                        |              |
| Not Reviewed                                                  |              |
| For more information, please visit <a href="#">Contact US</a> |              |
| China ROHS                                                    | Not Reviewed |
| ELV                                                           | Not Reviewed |
| RoHS Phthalates                                               | Not Reviewed |

Search Parts in this Series

130094 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300940007