

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940227](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Double Eye, Closed Mesh, Double Weave, Cable Diameter 76.20-88.65mm (3.000-3.490"), Approximate Break Strength 2394.97kg (5280 lbs)

Documents:
[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA

LR32159

General


Product Family Cable Grips
Series [130094](#)
Eye Type Double
O-Ring N/A
Overview [Support Grips](#)
Product Name Standard Duty
Type Support Grip
UPC 78678835010

Physical

Approximate Break Strength 2394.97kg (5280 lbs)
Bale Length 0.203m (8.00")
Body Style Straight
Cable Diameter 76.20-88.65mm (3.000-3.490")
Color - Grommet N/A
Gender N/A
Material - Body N/A
Material - Grip Non-magnetic Tin Bronze Wire
Mesh Length 0.66m (26.00")
Number of Holes N/A
Thread Size N/A

Material Info

Engineering Number 35010

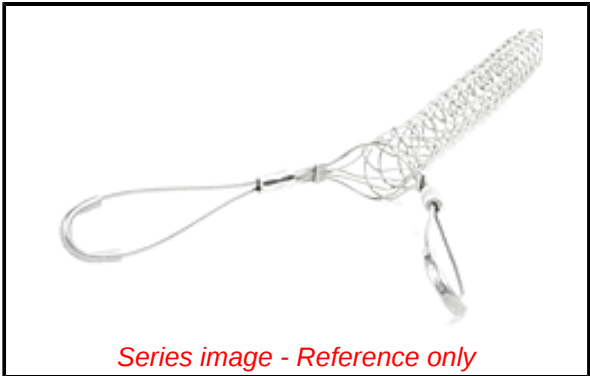

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1300940227](#)