

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940234](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Single Eye, Closed Mesh, Single Weave, Cable Diameter 19.05-25.15mm (.750-.990"), Approximate Break Strength 589.67kg (1300 lbs)


Documents:
[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR32159

General
Product Family Cable Grips
Series [130094](#)
Eye Type Single
O-Ring N/A
Overview [Support Grips](#)
Product Name Standard Duty
Type Support Grip
UPC 78678835032

Physical
Approximate Break Strength 589.67kg (1300 lbs)
Bale Length 0.203m (8.00")
Body Style Straight
Cable Diameter 19.05-25.15mm (.750-.990")
Color - Grommet N/A
Gender N/A
Material - Body N/A
Material - Grip Non-magnetic Tin Bronze Wire
Mesh Length 0.356m (14.00")
Net Weight 75.296/g
Number of Holes N/A
Thread Size N/A

Material Info
Engineering Number 35032

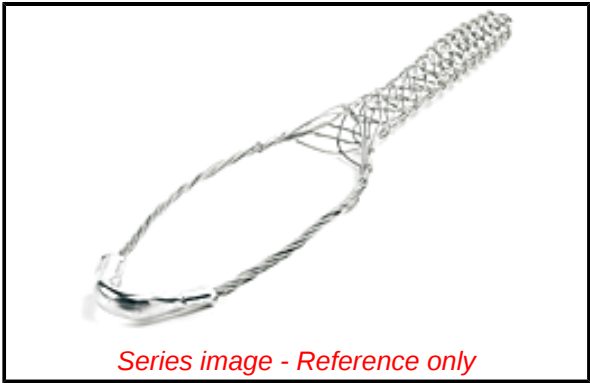

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[130094](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1300940234](#) [35032](#)