


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940235](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Single Eye, Closed Mesh, Single Weave, Cable Diameter 19.05-25.15mm (.750-.990"), Approximate Break Strength 589.67kg (1300 lbs), Stainless Steel

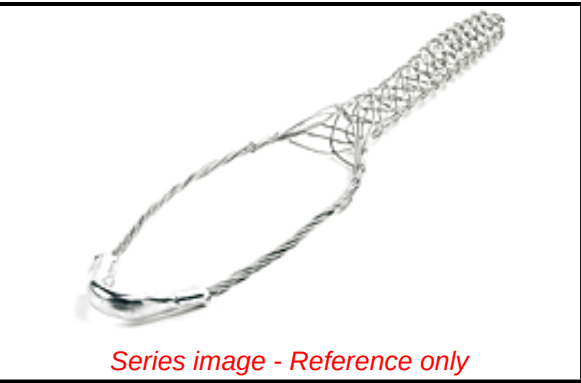

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable Grips
Series	130094
Eye Type	Single
NEMA Rating	NEMA 4
O-Ring	No
Overview	Support Grips
Product Name	Standard Duty
Type	Support Grip
UPC	78678809771
Physical	
Approximate Break Strength	598.74kg (1320 lbs)
Bale Length	0.203m (8.00")
Body Style	Straight
Cable Diameter	19.05-25.15mm (.750-.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Stainless Steel
Mesh Length	0.356m (14.00")
Net Weight	588.000/g
Number of Holes	N/A
Thread Size	N/A
Material Info	
Engineering Number	35032SS

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed For more information, please visit Contact US	China RoHS
China ROHS ELV RoHS Phthalates	Green Image Not Relevant Not Contained

Search Parts in this Series
[130094](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300940235