

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940236](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Single Eye, Closed Mesh, Single Weave, Cable Diameter 25.40-31.50mm (1.000-1.240"), Approximate Break Strength 762.04kg (1680 lbs)


Documents:
[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR32159

General
Product Family Cable Grips
Series [130094](#)
Eye Type Single
O-Ring N/A
Overview [Support Grips](#)
Product Name Standard Duty
Type Support Grip
UPC 78678835033

Physical
Approximate Break Strength 762.04kg (1680 lbs)
Bale Length 0.229m (9.00")
Body Style Straight
Cable Diameter 25.40-31.50mm (1.000-1.240")
Color - Grommet N/A
Gender N/A
Material - Body N/A
Material - Grip Non-magnetic Tin Bronze Wire
Mesh Length 0.38m (15.00")
Net Weight 588.000/g
Number of Holes N/A
Thread Size N/A

Material Info
Engineering Number 35033

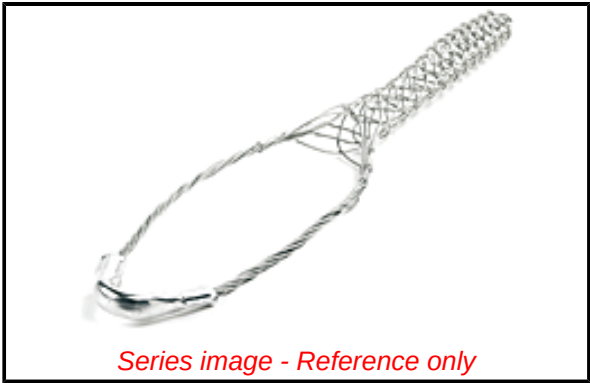

EU ELV
Not Reviewed

EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[130094](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300940236 35033