

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300940242

Status:


Active

Overview:

Support Grips

Description:

Standard Duty Support Grip, Single Eye, Closed Mesh, Single Weave, Cable Diameter 44.45-50.55mm (1.750-1.990"), Approximate Break Strength 1197.48kg (2640 lbs)

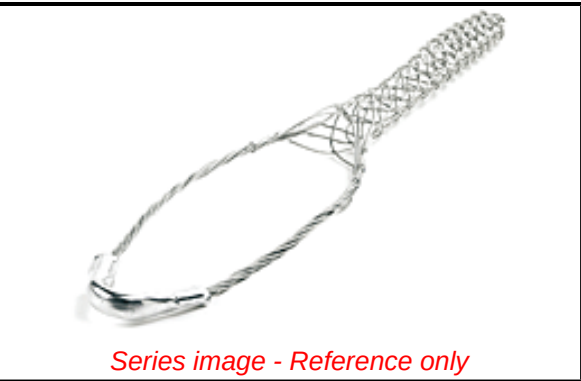

Documents:

Brochure (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR32159
General	
Product Family	Cable Grips
Series	130094
Eye Type	Single
O-Ring	N/A
Overview	Support Grips
Product Name	Standard Duty
Type	Support Grip
UPC	78678835036
Physical	
Approximate Break Strength	1197.48kg (2640 lbs)
Bale Length	0.356m (14.00")
Body Style	Straight
Cable Diameter	44.45-50.55mm (1.750-1.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.508m (20.00")
Net Weight	432.110/g
Number of Holes	N/A
Thread Size	N/A
Material Info	
Engineering Number	35036

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130094 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1300940242](#) [35036](#)