

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940258](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Offset Eye, Closed Mesh, Single Weave, Cable Diameter 25.40-31.50mm (1.000-1.240"), Approximate Break Strength 762.04kg (1680 lbs), Stainless Steel

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Cable Grips
Series	130094
Eye Type	Offset
NEMA Rating	NEMA 4
O-Ring	No
Overview	Support Grips
Product Name	Standard Duty
Type	Support Grip
UPC	78678809781

Physical

Approximate Break Strength	762.04kg (1680 lbs)
Bale Length	0.127m (5.00")
Body Style	Straight
Cable Diameter	25.40-31.50mm (1.000-1.240")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Stainless Steel
Mesh Length	0.38m (15.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number	35063SS
--------------------	---------

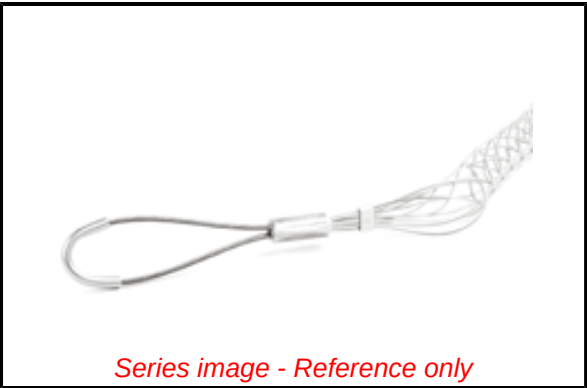

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130094](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300940258