

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300940305

Status:


Active

Overview:

Support Grips

Description:

Standard Duty Support Grip, Double Eye, Split Lace, Single Weave, Cable Diameter 63.50-75.95mm (2.500-2.990"), Approximate Break Strength 1524.07kg (3360 lbs), Stainless Steel

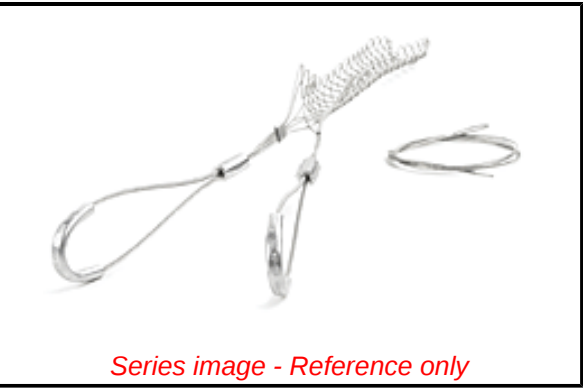

Series image - Reference only

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Grips
Series	130094
Eye Type	Double
NEMA Rating	NEMA 4
O-Ring	No
Overview	Support Grips
Product Name	Standard Duty
Type	Support Grip
UPC	78678897265
Physical	
Approximate Break Strength	1524.07kg (3360 lbs)
Bale Length	0.152m (6.00")
Body Style	Straight
Cable Diameter	63.50-75.95mm (2.500-2.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Stainless Steel
Mesh Length	0.61m (24.00")
Number of Holes	N/A
Thread Size	N/A
Material Info	
Engineering Number	35143SS

EU ELV Not Reviewed	
EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130094 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300940305