


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940371](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Double "U" Eye, Split Rod, Single Weave, Cable Diameter 19.05-25.15mm (.750-.990"), Approximate Break Strength 598.74kg (1320 lbs), Stainless Steel

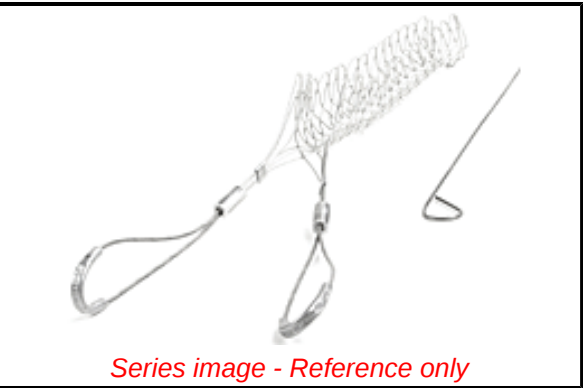

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable Grips
Series	130094
Eye Type	Double
NEMA Rating	NEMA 4
O-Ring	No
Overview	Support Grips
Product Name	Standard Duty
Type	Support Grip
UPC	78678809881
Physical	
Approximate Break Strength	598.74kg (1320 lbs)
Bale Length	0.102m (4.00")
Body Style	Straight
Cable Diameter	19.05-25.15mm (.750-.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Stainless Steel
Mesh Length	0.356m (14.00")
Number of Holes	N/A
Thread Size	N/A
Material Info	
Engineering Number	35272SS
Reference - Drawing Numbers	
Sales Drawing	SD-130094-044

EU ELV Not Reviewed	
EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[130094](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300940371](#)