

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300940477

Status:


Active

Overview:

Support Grips

Description:

Heavy Duty Support Grip, Double Eye, Double Weave, Split Lace, Cable Diameter 76.20-88.65mm (3.000-3.490"), Approximate Break Strength 2394.97kg (5280 lbs), Stainless Steel

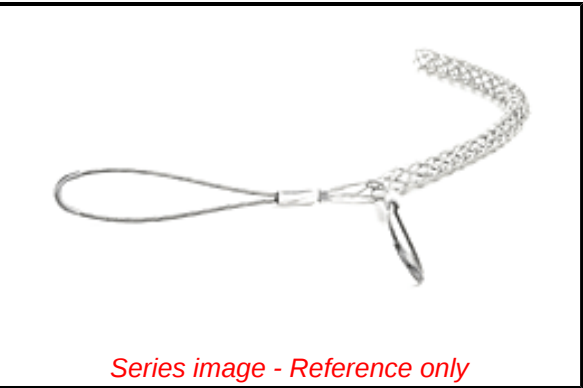

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Grips
Series	130094
Eye Type	Double
NEMA Rating	NEMA 4
O-Ring	No
Overview	Support Grips
Product Name	Heavy Duty
Type	Support Grip
UPC	78678809946
Physical	
Approximate Break Strength	2394.97kg (5280 lbs)
Bale Length	0.203m (8.00")
Body Style	Straight
Cable Diameter	76.20-88.65mm (3.000-3.490")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Stainless Steel
Mesh Length	0.66m (26.00")
Number of Holes	N/A
Thread Size	N/A
Material Info	
Engineering Number	35446SS

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130094 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300940477