


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301280117](#)
Status: **Active**
Overview: [Outlet Boxes](#)
Description: Woodhead FD Yellow Glass-Filled Polyester Box, Corrosion -resistant, (2) 19.05mm (.750") Threaded Knock-out Openings, GFCI 20A/125V, with Watertite Silicone Coverplate

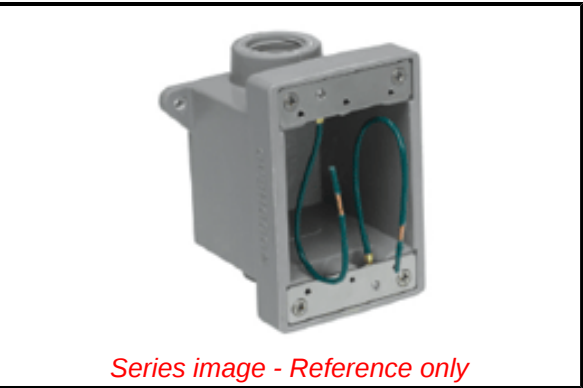

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

General
Product Family Power Distribution
Series [130128](#)
Enclosure Rating N/A
GFCI Reset N/A
Mounting Style Permanent
Open Neutral Relay N/A
Overview [Outlet Boxes](#)
Product Name Woodhead
Receptacle Type N/A
Type FD Box - Industrial Duty
UPC 78678815112

Physical
Cord Diameter N/A
Cord Grip Body Size N/A
Cord Length N/A
Feed-Thru No
Flip Lid No
Material - Housing PBT Glass-Filled
Number of Receptacles 0
Packaging Type Carton

Electrical
Cord Type N/A
Current - Maximum per Contact N/A
GFCI No
Ground Continuity Monitor No
NEMA Configuration N/A
Voltage - Maximum N/A

Material Info
Engineering Number 453GF

Reference - Drawing Numbers
Sales Drawing 1301280117-000

EU ELV
Not Reviewed

EU RoHS **China RoHS**
Not Reviewed
REACH SVHC
Not Reviewed
Halogen-Free
Status
Not Reviewed
For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[130128](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[130128-0117](#)