

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1301280119

Status:


Active

Overview:

Outlet Boxes

Description:

Woodhead FD Yellow Glass-Filled Polyester Box, Corrosion -resistant (2) 25.40mm (1.000") Threaded Knock-out Openings

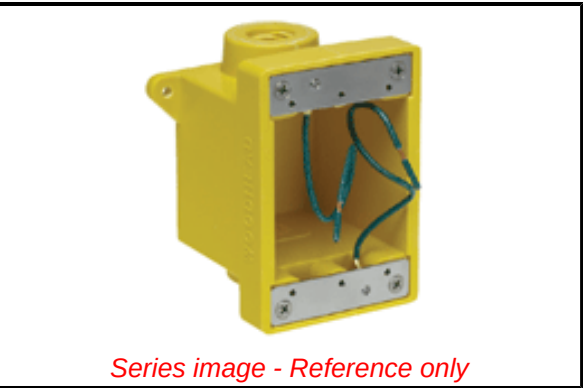

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Brochure (PDF)

Agency Certification	
CSA	LR32159
UL	E117594
General	
Product Family	Power Distribution
Series	130128
Enclosure Rating	N/A
GFCI Reset	N/A
Mounting Style	Permanent
Open Neutral Relay	N/A
Overview	Outlet Boxes
Product Name	Woodhead
Receptacle Type	N/A
Type	FD Box - Wet Location
UPC	78678877954
Physical	
Cord Diameter	N/A
Cord Grip Body Size	N/A
Cord Length	N/A
Feed-Thru	Yes
Flip Lid	No
Material - Housing	PBT Glass-Filled
Net Weight	448.149/g
Number of Receptacles	0
Packaging Type	Carton
Electrical	
Cord Type	N/A
Current - Maximum per Contact	N/A
GFCI	No
Ground Continuity Monitor	No
NEMA Configuration	N/A
Voltage - Maximum	N/A
Material Info	
Engineering Number	454CR
Reference - Drawing Numbers	
Sales Drawing	1301280113-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130128 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1301280119