

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1301370235

Status:


Active

Overview:

Watertite Extreme Wet-Location Wiring Solutions

Description:

Watertite GFCI Multiple Outlet FD Box, (1)NEMA 5-20 Duplex with Flip Lids, 15.24m (50.0') Cord Length, 14/3 SOOW Cord, NEMA 5-20 Watertite Plug

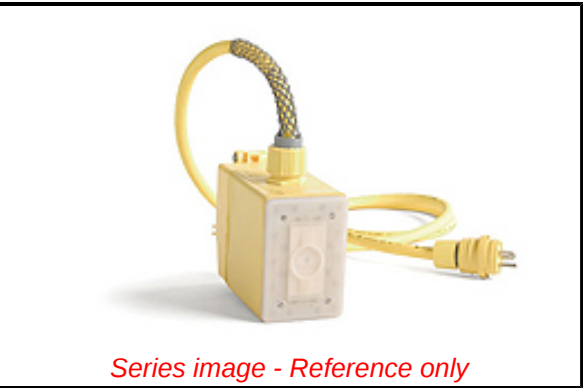

Documents:

Brochure (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Power Distribution
Series	130137
Enclosure Rating	NEMA 4X
GFCI Reset	Manual
Mounting Style	Portable
Open Neutral Relay	No
Overview	Watertite Extreme Wet-Location Wiring Solutions
Product Name	Watertite
Receptacle Type	Duplex
Type	GFCI Multiple Outlet Box
UPC	78678828306
Physical	
Cord Diameter	15.24mm (.600")
Cord Grip Body Size	F3 3/4"
Cord Length	15.24m (50.0')
Feed-Thru	No
Flip Lid	Yes
Material - Housing	Nylon
Number of Receptacles	1
Packaging Type	Carton
Electrical	
Cord Type	12/3 SOOW
Current - Maximum per Contact	20.0A
GFCI	Yes
Ground Continuity Monitor	No
NEMA Configuration	NEMA 5-20
Voltage - Maximum	120V
Material Info	
Engineering Number	3304GFB123

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130137 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1301370235