


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301540065](#)
Status: **Active**
Overview: [Heavy-Duty Industrial Wiring Devices](#)
Description: Super-Safeway Molded Y Cordset, 2 Pole/3 Wire SJOW Cordset, Cordset Length 0.91m (3.0'), NEMA L5-20, 125V, Inline GFCI

Documents:
[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Wiring Devices
Series	130154
IP Rating	N/A
NEMA Configuration	NEMA L5-20
Overview	Heavy-Duty Industrial Wiring Devices
Product Name	Super-Safeway
Receptacle Type	Duplex
Specialty	N/A
Type	Molded Y Cordset
UPC	78678839001
Physical	
Flange	No
Flip Lid	No
Gender	Male-Female
Length	0.91m (3.0')
Locking Blade	Yes
Poles	2-pole/3-wire
Electrical	
Cord Type	12/3 SJOW
Current - Maximum per Contact	20.0A
GFCI	Yes-In-line
Lighted Connector	No
Voltage - Maximum	125V
Material Info	
Engineering Number	2647-Y-IN

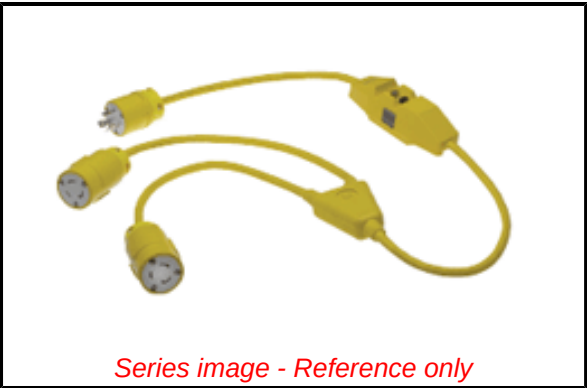

EU ELV Not Reviewed	
EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[130154](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1301540065