

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [1552100015](#)  
**Status:** **Active**  
**Overview:** [Flamar Standard and Custom Cables for Industrial Automation](#)  
**Description:** Flamar Sensor Cable, PVC Jacket, Unshielded, 4 Circuits, 0.25mm<sup>2</sup> / 24 AWG, 4.80mm (.189") Diameter, 1500.0m (4921.26') Length, Black

**Documents:**

[Product Specification 1552100001-P1E \(PDF\)](#)      [RoHS Certificate of Compliance \(PDF\)](#)  
[Brochure \(PDF\)](#)

**Agency Certification**

UL      E172949

**General**

Product Family      Cable  
Series      [155210](#)  
Crimp Quality Equipment      Yes  
Geographic Area      Global  
Overview      [Flamar Standard and Custom Cables for Industrial Automation](#)  
Product Name      Flamar, Signal and Control  
UPC      889056448734

**Physical**

Bending Radius - Minimum      > 15xOD  
Cable Length      1500.0m  
Circuits (Loaded)      4  
Color - Cable Jacket      Black  
Insulation      TPE  
Material - Outer Jacket      PVC  
Net Weight      0.031/kg  
Outer Jacket Diameter      4.80mm  
Packaging Type      Reel  
Temperature Range - Operating      +5° to +80°C  
Wire Size AWG      24  
Wire Size mm<sup>2</sup>      0.25  
Wire/Cable Type      UL AWM 2464 / CSA

**Electrical**


Current - Maximum per Contact      Contact Molex  
Voltage - Maximum      300V

**Material Info**

Engineering Number      1X1500M

**Reference - Drawing Numbers**

Product Specification      1552100001-P1E

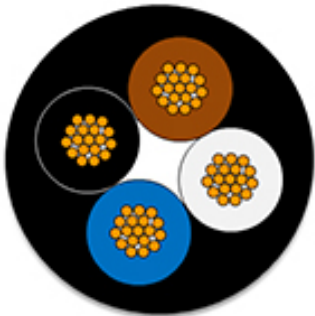

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**China RoHS**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

|                 |               |
|-----------------|---------------|
| China ROHS      | Green Image   |
| ELV             | Not Relevant  |
| RoHS Phthalates | Not Contained |

**Search Parts in this Series**

[155210](#) Series

**Use With**

Nano-Change (M8) [120091](#) , Micro-Change (M12) [120071](#) , Ultra-Lock (M12) [120085](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[155210-0015](#)