


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1553110011](#)
Status: **Active**
Overview: [Flamar Standard and Custom Cables for Industrial Automation](#)
Description: Flamar Power Cable, PVC Jacket, Braided Shielding Overall, 4 Circuits, 6.00mm² with Green-Yellow Ground / 10 AWG with Green-Yellow Ground, 14.50mm (.177") Diameter, 500.0m (1640.42') Length, Orange

Documents:
[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable
Series	<u>155311</u>
Crimp Quality Equipment	Yes
Geographic Area	Global
Overview	<u>Flamar Standard and Custom Cables for Industrial Automation</u>
Product Name	Flamar, Servo Motor
UPC	889056459556
Physical	
Bending Radius - Minimum	> 15xOD
Cable Length	500.0m
Circuits (Loaded)	4
Color - Cable Jacket	Orange
Insulation	TPE
Material - Outer Jacket	PVC
Net Weight	0.010/g
Outer Jacket Diameter	14.50mm
Packaging Type	Reel
Temperature Range - Operating	+5° to +80°C
Wire Size AWG	10
Wire Size mm ²	6.00
Wire/Cable Type	UL AWM 2570 / CSA
Electrical	
Current - Maximum per Contact	Contact Molex
Voltage - Maximum	1000V
Material Info	
Engineering Number	1X500M

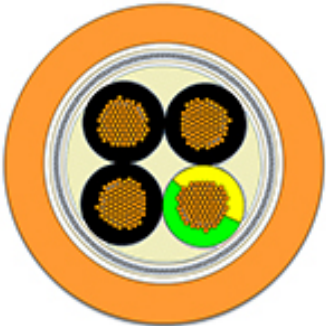

Series image - Reference only

EU ELV Not Reviewed	
EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[155311](#) Series

Use With
Brad M23 [120230](#) , [120233](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

155311-0011