


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1553210008](#)
Status: **Active**
Overview: [Flamar Standard and Custom Cables for Industrial Automation](#)
Description: Flamar Power Cable, WSOR Jacket, Braided Shielding Overall, 4 Circuits, 4.00mm² with Green-Yellow Ground / 12 AWG with Green-Yellow Ground, 12.20mm (.480") Diameter, 500.0m (1640.42') Length, Orange

Documents:
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable
Series	155321
Crimp Quality Equipment	Yes
Geographic Area	Global
Overview	Flamar Standard and Custom Cables for Industrial Automation
Product Name	Flamar, Servo Motor
UPC	889056460408
Physical	
Bending Radius - Minimum	> 10xOD
Cable Length	500.0m
Circuits (Loaded)	4
Color - Cable Jacket	Orange
Insulation	TPE
Material - Outer Jacket	WSOR
Net Weight	0.010/g
Outer Jacket Diameter	12.20mm
Packaging Type	Reel
Temperature Range - Operating	-25° to +80°C
Wire Size AWG	12
Wire Size mm ²	4.00
Wire/Cable Type	UL AWM 21939 / CSA
Electrical	
Current - Maximum per Contact	Contact Molex
Voltage - Maximum	1000V
Material Info	
Engineering Number	1X500M

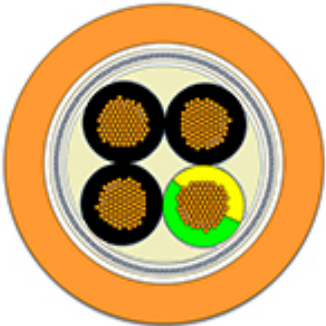

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[155321](#) Series

Use With
Brad M23 [120230](#) , [120233](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

155321-0008