


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1553210009](#)
Status: **Active**
Overview: [Flamar Standard and Custom Cables for Industrial Automation](#)
Description: Flamar Power Cable, WSOR Jacket, Braided Shielding Overall, 4 Circuits, 4.00mm² with Green-Yellow Ground / 12 AWG with Green-Yellow Ground, 12.20mm (.480") Diameter, 1000.0m (3280.83') Length, Orange

Documents:
[Product Specification 1553210001-P1E \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification	
UL	E172949
General	
Product Family	Cable
Series	155321
Crimp Quality Equipment	Yes
Geographic Area	Global
Overview	Flamar Standard and Custom Cables for Industrial Automation
Product Name	Flamar, Servo Motor
UPC	889056460415
Physical	
Bending Radius - Minimum	> 10xOD
Cable Length	1000.0m
Circuits (Loaded)	4
Color - Cable Jacket	Orange
Insulation	TPE
Material - Outer Jacket	WSOR
Net Weight	0.288/kg
Outer Jacket Diameter	12.20mm
Packaging Type	Wooden Drum
Temperature Range - Operating	-25° to +80°C
Wire Size AWG	12
Wire Size mm ²	4.00
Wire/Cable Type	UL AWM 21939 / CSA
Electrical	
Current - Maximum per Contact	Contact Molex
Voltage - Maximum	1000V
Material Info	
Engineering Number	1X1000M
Reference - Drawing Numbers	
Product Specification	1553210001-P1E

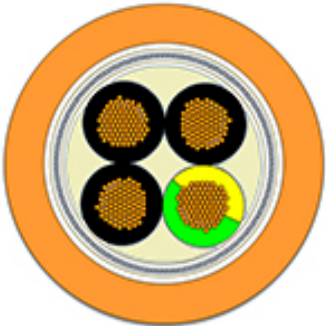

Series image - Reference only

EU ELV Not Reviewed	
EU RoHS Missing Compliance Data	China RoHS
REACH SVHC Not Reviewed	
Halogen-Free Status Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Reviewed
RoHS Phthalates	Missing Compliance Data

Search Parts in this Series
[155321](#) Series

Use With
Brad M23 [120230](#) , [120233](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

155321-0009