

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1700177002

Status:


Active

Overview:

SFP+ and SFP Interconnect Solutions

Description:

Small Form-factor Pluggable Plus (SFP+) Stacked 2-by-8 Multi-Port Press Fit Connector with 2 Inner Lightpipe Ports, Elastomeric Gasket, 608 Circuits, Tin (Sn) Tails, Enhanced EMI

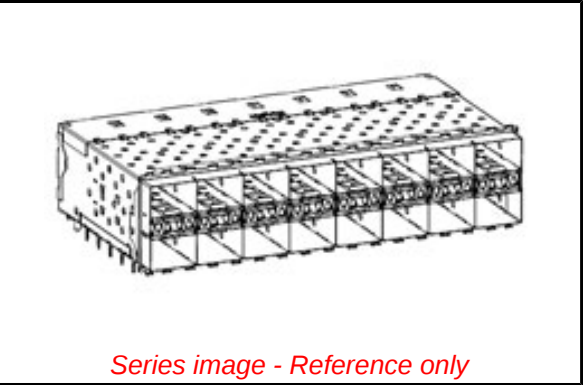

Documents:	
3D Model	Application Specification AS-75310-001-001 (PDF)
Drawing (PDF)	Application Specification AS-76090-001-001 (PDF)
3D Model (PDF)	Packaging Specification PK-76352-001-001 (PDF)
Product Specification PS-75310-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	I/O Connectors
Series	170017
Application	Module-to-Board
Component Type	Receptacle
Overview	SFP+ and SFP Interconnect Solutions
Product Name	SFP Plus
Type	N/A
UPC	884982215054
Physical	
Boot Color	N/A
Circuits (Loaded)	608
Circuits (maximum)	608
Circuits Detail	608
Durability (mating cycles max)	100
Flammability	94V-0
Gender	Female
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Plating Mating	Gold
Net Weight	187.796/g
Number of Rows	2
Orientation	Right Angle
PC Tail Length	2.07mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.57mm
Packaging Type	Tray
Panel Mount	No
Pitch - Mating Interface	0.80mm
Pitch - Termination Interface	0.80mm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	16
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +85°C
Termination Interface: Style	Through Hole - Compliant Pin
Waterproof / Dustproof	No
Electrical	

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

170017 Series

Current - Maximum per Contact	0.5A
Grounding to Panel	None
Shield Type	EMI Gasket, Full Shield
Shielded	Yes
Voltage - Maximum	120V AC (RMS)/DC
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-75310-001-001, AS-76090-001-001
Packaging Specification	PK-76352-001-001
Product Specification	PS-75310-001-001
Sales Drawing	SD-170017-002-001

This document was generated on 10/04/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[170017-7002](#)