

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1727040006

Status:


Active

Overview:

FCT D-Sub Connectors

Description:

FCT Standard-Density D-Sub Crimp Housing, Female, Shell without Dimples, 37 Circuits

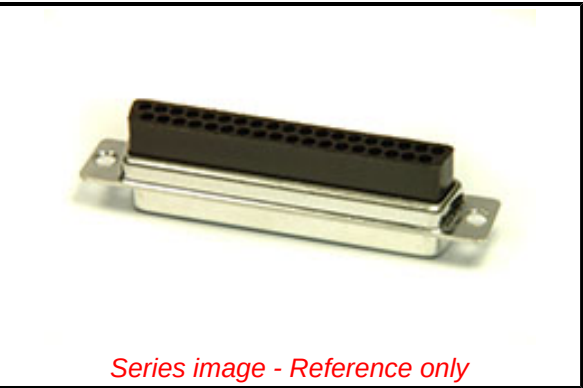

Series image - Reference only

Documents:

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

Brochure (PDF)

General	
Product Family	D-Sub Products
Series	172704
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	Standard Density
UPC	889056019071
Physical	
Circuits (Loaded)	0
Circuits (maximum)	37
Color - Resin	Black
Gender	Female
Material - Resin	PBT, Polyamide
Material - Shell	Steel
Net Weight	13.000/g
Number of Rows	2
Orientation	Straight
PCB Locator	No
PCB Retention	None
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Flange
Pitch - Mating Interface	2.84mm
Pitch - Termination Interface	2.84mm
Plating - Shell	Tin
Polarized to Mating Part	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +115°C
Termination Style	Crimp
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20
Wire Size AWG	18, 20, 22, 24, 26, 28
Material Info	
Engineering Number	FL37S7-K121

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

172704 Series

Mates With

FCT Standard-Density D-Sub, Size 4, 37 Position, Plug

Use With

FCT Standard-Density Female Crimp Contacts 1731120214 , 1731120215 , 1731120216

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[172704-0006](#)