

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1727040078

Status:


Active

Overview:

FCT D-Sub Connectors

Description:

FCT Standard-Density D-Sub Connector, Female, Straight, Solder Cup, Gold Plating, 500 Mating Cycles, 9 Circuits

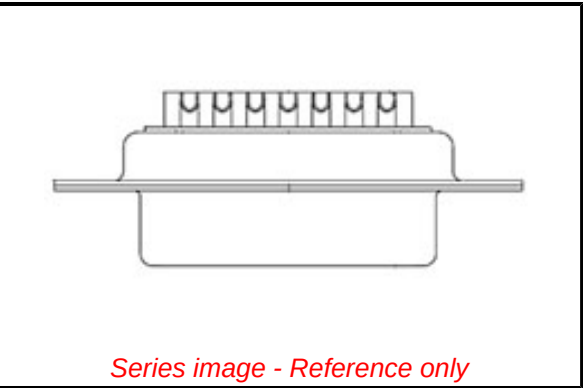

Documents:

Product Specification 1727040001-PS-000 (PDF)

Brochure (PDF)

Test Summary 1727040000-TS-000 (PDF)

RoHS Certificate of Compliance (PDF)

Datasheet (PDF)

General	
Product Family	D-Sub Products
Series	172704
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	Standard Density
UPC	889056019897
Physical	
Circuits (Loaded)	9
Circuits (maximum)	9
Color - Resin	White
Durability (mating cycles max)	500
Gender	Female
Material - Contact	Copper Alloy
Material - Resin	PBT
Material - Shell	Steel
Net Weight	5.700/g
Number of Rows	2
Orientation	Straight
PCB Locator	No
PCB Retention	None
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Flange
Pitch - Mating Interface	2.84mm
Pitch - Termination Interface	2.84mm
Plating - Contact	Gold over Nickel
Plating - Shell	Tin
Polarized to Mating Part	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +125°C
Termination Style	Solder Cup
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20
Wire Size AWG	20
Electrical	
Current - Maximum per Contact	7.5A
Material Info	
Engineering Number	F09S0G1
Reference - Drawing Numbers	

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 7(c)-I,6(c)

REACH SVHC

Contained Per - ECHA_01_2020 (16 January 2020)

lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit Contact US

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

172704 Series

Mates With

FCT Standard-Density D-Sub, Size 1, 9 Position, Plug

This document was generated on 07/30/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[172704-0078](#)