


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1805800101](#)
Status: **Active**
Overview: LED Array Holders, Dual-Ended Wire Trap
Description: LED Array Holder for 16.00 by 19.00mm COB, Rectangular Version, Gold (Au) Plating, PBT, One-Piece Design, White

Documents:	
3D Model	Application Specification AS-180328-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-180586-001-001 (PDF)
3D Model (PDF)	Test Summary TS-180155-001-001 (PDF)
Product Specification PS-180580-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E345583
General	
Product Family	Solid State Lighting
Series	180580
Array Type	Nichia
Beam Angle	N/A
Height	4.10mm
Overview	LED Array Holders, Dual-Ended Wire Trap
Product Name	Wire Trap Holder
Type	LED COB Array Holder
UPC	887191653433
Physical	
Base Type	N/A
Color Rendering Index (CRI)	N/A
Correlated Color Temp (CCT)	N/A
Depth	0.90mm
Flammability	94V-0
Lamp Type	N/A
Material - Metal	Copper Alloy
Mounting Style	Screws
Net Weight	8.868/g
Packaging Type	Tray
Electrical	
Lamp Wattage - Maximum	N/A
Lumens	N/A
Voltage (Fixture) - Maximum	600V DC
Wiring Style	Poke In Wire Traps
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-180328-001-001
Packaging Specification	PK-180586-001-001
Product Specification	PS-180580-001-001
Sales Drawing	SD-180580-001
Test Summary	TS-180155-001-001

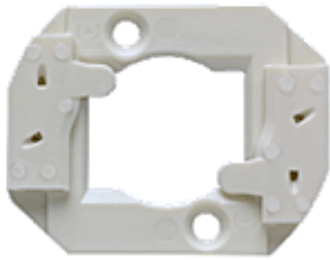

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ECHA_01_2020 (16 January 2020)	
Halogen-Free Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[180580](#) Series

Use With
19.00mm by 16.00mm COB

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

180580-0101