

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION


Part Number: [2000960261](#)
Status: **Active**
Overview: [stAK50h Connection System](#)
Description: TAK50 Receptacle Terminal, Unsealed, S-Grip, B-Wind, Right Reel Payoff
Replacement Part Number : <http://www.molex.com/molex/search/partSearch?pQuery=&sType=p&query=20009632612000963261>

Documents:
[Drawing \(PDF\)](#)
[Product Specification 2000960000-000 \(PDF\)](#)
[Application Specification 2000960001-000 \(PDF\)](#)
[Application Specification 2000960001-AS-CH-000 \(PDF\)](#)
[Packaging Specification 313025040-000 \(PDF\)](#)
[Test Summary 2000960002-000 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Crimp Terminals
Series	200096
Application	Automotive, Signal, Wire-to-Board
Comments	Stainless Steel Hood/Sleeve Right Reel Payoff For automatic and semi-automatic crimping, use Left Reel Payoff terminals. See Sales Drawing for Left Reel Payoff Part Numbers.
Crimp Quality Equipment	Yes
Overview	stAK50h Connection System
Product Name	TAK50
Replacement Part Number	2000963261
UPC	191128074742
Physical	
Durability (mating cycles max)	10
Gender	Female
Grip Code	S
Material - Metal	Copper Alloy, Stainless Steel
Material - Plating Mating	Tin
Net Weight	0.055/g
Packaging Type	Reel
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.95-1.05mm
Wire Size AWG	N/A
Wire Size mm²	0.13
Electrical	
Current - Maximum per Contact	3.0A
Voltage - Maximum	14V DC

Material Info

Reference - Drawing Numbers	
Application Specification	2000960001-000, 2000960001-AS-CH-000
Packaging Specification	313025040-000
Product Specification	2000960000-000
Sales Drawing	2000960001-000
Test Summary	2000960002-000

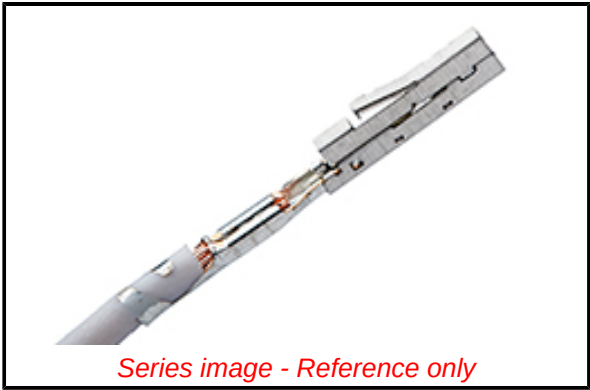

EU ELV
Compliant

EU RoHS
Compliant
REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free
Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[200096](#) Series

Use With
stAK50h Hybrid Receptacle [160014](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Extraction Tool for stAK50h Connector System	2002220100
Hand Crimp Tool for TAK50 Receptacle Crimp Terminals, Small Grip, 0.13mm² Wire	2133092000

This document was generated on 08/27/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[200096-0261](#)