

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2001991320

Status:


Active

Overview:

Application Tooling

Description:

Extraction Tool for 1-by-1 QSFP-DD and BiPass Single Port Connector with Press-Fit Tails

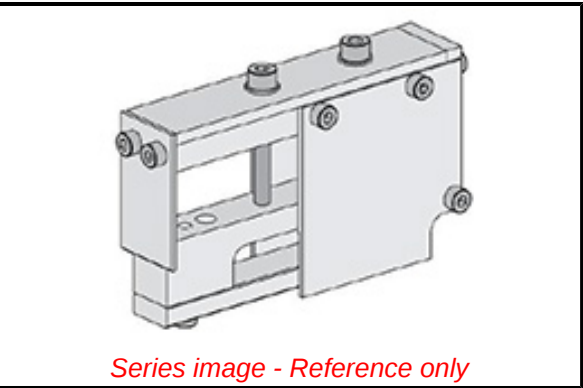

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207123
Comments	See Tooling Specification (PDF) Above
Function	Extraction
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	BiPass, QSFP-DD
Tool Type	Press-Fit Extraction Tool
UPC	191128919319
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info	
Reference - Drawing Numbers	
Application Tooling Documents	2001991320-000

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207123 Series

Application Tooling Description	FAQ Product #
BiPass 1-by-1 zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Open Top with Heat Sink and Lightpipe, 75.00mm Pico-Clasp / 150.00mm NearStack Cable Lengths	1111311911
BiPass 1-by-1 zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Open Top with Heat Sink and Lightpipe, 75.00mm Pico-Clasp / 200.00mm	1111311912

NearStack Cable Lengths	
BiPass 1-by-1	<u>1111311913</u>
zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Open Top with Heat Sink and Lightpipe, 75.00mm Pico-Clasp / 300.00mm	
NearStack Cable Lengths	
BiPass 1-by-1	<u>1111311914</u>
zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Open Top with Heat Sink and Lightpipe, 75.00mm Pico-Clasp / 400.00mm	
NearStack Cable Lengths	
BiPass 1-by-1	<u>1111311915</u>
zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Open Top with Heat Sink and Lightpipe, 75.00mm Pico-Clasp / 500.00mm	
NearStack Cable Lengths	
BiPass 1-by-1	<u>1111311920</u>
zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Closed Top, 75.00mm Pico-Clasp / 150.00mm	
NearStack Cable Lengths	
BiPass 1-by-1	<u>1111311921</u>
zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Closed Top, 75.00mm Pico-Clasp / 200.00mm	
NearStack Cable Lengths	
BiPass 1-by-1	<u>1111311922</u>
zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Closed Top, 75.00mm Pico-	

	Clasp / 300.00mm NearStack Cable Lengths BiPass 1-by-1	<u>1111311923</u>
	zQSFP+-to- NearStack (8- Differential Pair) and Pico-Clasp Cable Assembly, Closed Top, 75.00mm Pico- Clasp / 400.00mm NearStack Cable Lengths BiPass 1-by-1	<u>1111311924</u>
	zQSFP+-to- NearStack (8- Differential Pair) and Pico-Clasp Cable Assembly, Closed Top, 75.00mm Pico- Clasp / 500.00mm NearStack Cable Lengths BiPass 1-by-1	<u>1111311930</u>
	zQSFP+-to- NearStack (8- Differential Pair) and Pico-Clasp Cable Assembly, Closed Top with Lightpipe, 75.00mm Pico- Clasp / 150.00mm NearStack Cable Lengths BiPass 1-by-1	<u>1111311931</u>
	zQSFP+-to- NearStack (8- Differential Pair) and Pico-Clasp Cable Assembly, Closed Top with Lightpipe, 75.00mm Pico- Clasp / 200.00mm NearStack Cable Lengths BiPass 1-by-1	<u>1111311932</u>
	zQSFP+-to- NearStack (8- Differential Pair) and Pico-Clasp Cable Assembly, Closed Top with Lightpipe, 75.00mm Pico- Clasp / 300.00mm NearStack Cable Lengths BiPass 1-by-1	<u>1111311933</u>
	zQSFP+-to- NearStack (8- Differential Pair) and Pico-Clasp Cable Assembly, Closed Top with Lightpipe, 75.00mm Pico- Clasp / 400.00mm	

NearStack Cable Lengths	
BiPass 1-by-1	<u>1111311934</u>
zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Closed Top with Lightpipe, 75.00mm Pico-Clasp / 500.00mm	
NearStack Cable Lengths	
BiPass 1-by-1	<u>1111311940</u>
zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Open Top with Heat Sink, 75.00mm Pico-Clasp / 150.00mm	
NearStack Cable Lengths	
BiPass 1-by-1	<u>1111311941</u>
zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Open Top with Heat Sink, 75.00mm Pico-Clasp / 200.00mm	
NearStack Cable Lengths	
BiPass 1-by-1	<u>1111311942</u>
zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Open Top with Heat Sink, 75.00mm Pico-Clasp / 300.00mm	
NearStack Cable Lengths	
BiPass 1-by-1	<u>1111311943</u>
zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Open Top with Heat Sink, 75.00mm Pico-Clasp / 400.00mm	
NearStack Cable Lengths	
BiPass 1-by-1	<u>1111311944</u>
zQSFP+-to-NearStack (8-Differential Pair) and Pico-Clasp Cable Assembly, Open Top with Heat Sink, 75.00mm Pico-	

	Clasp / 500.00mm	
	NearStack Cable	
	Lengths	
	QSFP-DD Cage	<u>2031431243</u>
	Assembly, 1-by-1,	
	Closed Top, Spring	
	Fingers, No Rear	
	Legs, with Press-Fit	
	Pins	
	QSFP-DD Cage	<u>2031431244</u>
	Assembly, 1-by-1,	
	Closed Top, Spring	
	Fingers, One Rear	
	Leg, with Press-Fit	
	Pins	
	QSFP-DD Cage	<u>2031431254</u>
	Assembly, 1-by-1,	
	Open Top, Spring	
	Fingers, No Rear	
	Legs, with Press-Fit	
	Pins	
	QSFP-DD Cage	<u>2031431255</u>
	Assembly, 1-by-1,	
	Open Top, Spring	
	Fingers, One Rear	
	Leg, with Press-Fit	
	Pins	
	QSFP-DD Cage	<u>2031431256</u>
	Assembly, 1-by-1,	
	Open Top, Spring	
	Fingers, Two Rear	
	Legs, with Press-Fit	
	Pins	
	QSFP-DD Cage	<u>2031431349</u>
	Assembly, 1-by-1,	
	PCI Fin Heat Sink,	
	Spring Fingers, No	
	Rear Legs, with	
	Press-Fit Pins	
	QSFP-DD Cage	<u>2031431350</u>
	Assembly, 1-by-1,	
	SAN Fin Heat Sink,	
	Spring Fingers, No	
	Rear Legs, with	
	Press-Fit Pins	
	QSFP-DD Cage	<u>2031431351</u>
	Assembly, 1-by-1,	
	NET Fin Heat Sink,	
	Spring Fingers, No	
	Rear Legs, with	
	Press-Fit Pins	
	QSFP-DD Cage	<u>2031431352</u>
	Assembly, 1-by-1,	
	PCI Fin Heat Sink,	
	Spring Fingers,	
	One Rear Leg, with	
	Press-Fit Pins	
	QSFP-DD Cage	<u>2031431353</u>
	Assembly, 1-by-1,	
	SAN Fin Heat Sink,	
	Spring Fingers,	
	One Rear Leg, with	
	Press-Fit Pins	
	QSFP-DD Cage	<u>2031431354</u>
	Assembly, 1-by-1,	

	NET Fin Heat Sink, Spring Fingers, One Rear Leg, with Press-Fit Pins QSFP-DD Cage	<u>2031431355</u>
	Assembly, 1-by-1, PCI Fin Heat Sink, Spring Fingers, Two Rear Legs, with Press-Fit Pins QSFP-DD Cage	<u>2031431356</u>
	Assembly, 1-by-1, SAN Fin Heat Sink, Spring Fingers, Two Rear Legs, with Press-Fit Pins QSFP-DD Cage	<u>2031431357</u>
	Assembly, 1-by-1, NET Fin Heat Sink, Spring Fingers, Two Rear Legs, with Press-Fit Pins BiPass 1-by-1	<u>2084261002</u>
	zQSFP+-to- NearStack (8- Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 150.00mm Cable Length BiPass 1-by-1	<u>2084261003</u>
	zQSFP+-to- NearStack (8- Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 200.00mm Cable Length BiPass 1-by-1	<u>2084261004</u>
	zQSFP+-to- NearStack (8- Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 300.00mm Cable Length BiPass 1-by-1	<u>2084261005</u>
	zQSFP+-to- NearStack (8- Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 400.00mm Cable Length BiPass 1-by-1	<u>2084261006</u>
	zQSFP+-to- NearStack (8- Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount,	

	450.00mm Cable Length	
	BiPass 1-by-1	<u>2084261007</u>
	zQSFP+-to-NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 500.00mm Cable Length	
	BiPass 1-by-1	<u>2084261502</u>
	zQSFP+-to-NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations), 150.00mm Cable Length	
	BiPass 1-by-1	<u>2084261503</u>
	zQSFP+-to-NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations), 200.00mm Cable Length	
	BiPass 1-by-1	<u>2084261504</u>
	zQSFP+-to-NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations), 300.00mm Cable Length	
	BiPass 1-by-1	<u>2084261505</u>
	zQSFP+-to-NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations), 400.00mm Cable Length	
	BiPass 1-by-1	<u>2084261506</u>
	zQSFP+-to-NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations),	

	450.00mm Cable Length	
	BiPass 1-by-1	<u>2084261507</u>
	zQSFP+-to-NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations), 500.00mm Cable Length	
	BiPass 1-by-1	<u>2084731002</u>
	QSFP-DD-to-2 NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 150.00mm Cable Length	
	BiPass 1-by-1	<u>2084731003</u>
	QSFP-DD-to-2 NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 200.00mm Cable Length	
	BiPass 1-by-1	<u>2084731004</u>
	QSFP-DD-to-2 NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 300.00mm Cable Length	
	BiPass 1-by-1	<u>2084731005</u>
	QSFP-DD-to-2 NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 400.00mm Cable Length	
	BiPass 1-by-1	<u>2084731006</u>
	QSFP-DD-to-2 NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 450.00mm Cable Length	
	BiPass 1-by-1	<u>2084731007</u>
	QSFP-DD-to-2 NearStack (8-Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount,	

	500.00mm Cable Length	
	BiPass 1-by-1	<u>2084731502</u>
	QSFP-DD-to-2	
	NearStack (8-Differential Pair)	
	Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations),	
	150.00mm Cable Length	
	BiPass 1-by-1	<u>2084731503</u>
	QSFP-DD-to-2	
	NearStack (8-Differential Pair)	
	Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations),	
	200.00mm Cable Length	
	BiPass 1-by-1	<u>2084731504</u>
	QSFP-DD-to-2	
	NearStack (8-Differential Pair)	
	Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations),	
	300.00mm Cable Length	
	BiPass 1-by-1	<u>2084731505</u>
	QSFP-DD-to-2	
	NearStack (8-Differential Pair)	
	Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations),	
	400.00mm Cable Length	
	BiPass 1-by-1	<u>2084731506</u>
	QSFP-DD-to-2	
	NearStack (8-Differential Pair)	
	Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations),	
	450.00mm Cable Length	
	BiPass 1-by-1	<u>2084731507</u>
	QSFP-DD-to-2	
	NearStack (8-Differential Pair)	
	Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly	

Configurations), 500.00mm Cable Length	
BiPass 1-by-1	<u>2093511002</u>
QSFP-DD-to- NearStack (16- Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 150.00mm Cable Length	
BiPass 1-by-1	<u>2093511003</u>
QSFP-DD-to- NearStack (16- Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 200.00mm Cable Length	
BiPass 1-by-1	<u>2093511004</u>
QSFP-DD-to- NearStack (16- Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 300.00mm Cable Length	
BiPass 1-by-1	<u>2093511005</u>
QSFP-DD-to- NearStack (16- Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 400.00mm Cable Length	
BiPass 1-by-1	<u>2093511006</u>
QSFP-DD-to- NearStack (16- Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 450.00mm Cable Length	
BiPass 1-by-1	<u>2093511007</u>
QSFP-DD-to- NearStack (16- Differential Pair) Cable Assembly, Open Top with Heat Sink, Top Mount, 500.00mm Cable Length	
BiPass 1-by-1	<u>2093511502</u>
QSFP-DD-to- NearStack (16- Differential Pair) Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly	

Configurations), 150.00mm Cable Length	
BiPass 1-by-1	<u>2093511503</u>
QSFP-DD-to- NearStack (16- Differential Pair) Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations), 200.00mm Cable Length	
BiPass 1-by-1	<u>2093511504</u>
QSFP-DD-to- NearStack (16- Differential Pair) Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations), 300.00mm Cable Length	
BiPass 1-by-1	<u>2093511505</u>
QSFP-DD-to- NearStack (16- Differential Pair) Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations), 400.00mm Cable Length	
BiPass 1-by-1	<u>2093511506</u>
QSFP-DD-to- NearStack (16- Differential Pair) Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations), 450.00mm Cable Length	
BiPass 1-by-1	<u>2093511507</u>
QSFP-DD-to- NearStack (16- Differential Pair) Cable Assembly, Open Top with Heat Sink, Bottom Mount (for Belly-to-Belly Configurations), 500.00mm Cable Length	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[200199-1320](#)