

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2016066163

Status:


Active

Overview:

High-Current, Universal-Clamp Terminal Blocks

Description:

High Current Universal Clamp Terminal Block, 35.00mm DIN-rail Mount, 150.0A / 600V, Grey Housing and Cover, 3 Circuits

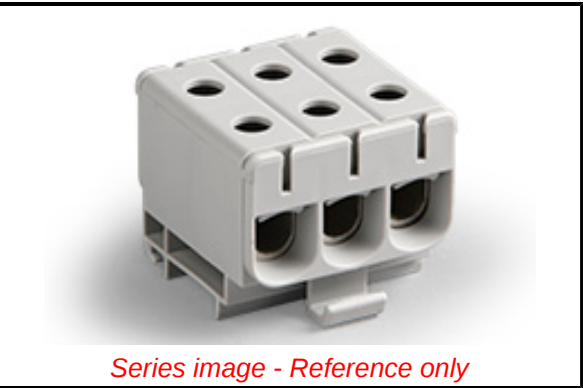

Series image - Reference only

|                                |                                                      |
|--------------------------------|------------------------------------------------------|
| Documents:                     |                                                      |
| <a href="#">3D Model</a>       | <a href="#">RoHS Certificate of Compliance (PDF)</a> |
| <a href="#">3D Model (PDF)</a> | <a href="#">Product Literature (PDF)</a>             |
| <a href="#">Drawing (PDF)</a>  |                                                      |

|                                |                                               |
|--------------------------------|-----------------------------------------------|
| General                        |                                               |
| Product Family                 | Terminal Blocks                               |
| Series                         | 201606                                        |
| Application                    | Wire-to-Wire                                  |
| Component Type                 | One Piece                                     |
| Overview                       | High-Current, Universal-Clamp Terminal Blocks |
| Product Name                   | Universal Clamp                               |
| Type                           | Universal Clamp                               |
| UPC                            | 78172551095                                   |
| Physical                       |                                               |
| Circuits (Loaded)              | 3                                             |
| Circuits (maximum)             | 3                                             |
| Color - Resin                  | Grey                                          |
| Entry Angle                    | Horizontal                                    |
| Lock to Mating Part            | None                                          |
| Material - Metal               | Aluminum                                      |
| Material - Plating Mating      | Tin                                           |
| Material - Plating Termination | Tin                                           |
| Material - Resin               | Polyamide                                     |
| Number of Rows                 | 3                                             |
| Orientation                    | Vertical                                      |
| Panel Mount                    | No                                            |
| Pitch - Mating Interface       | N/A                                           |
| Polarized to Mating Part       | N/A                                           |
| Stackable                      | No                                            |
| Temperature Range - Operating  | -40° to +105°C                                |
| Termination Interface: Style   | Screw                                         |
| Wire Size AWG                  | 1/0-6, 6+6, 8+8+8                             |
| Wire Size mm²                  | 13.00+13.00, 13.00-53.00, 8.30+8.30+8.30      |
| Electrical                     |                                               |
| Current - Maximum per Contact  | 150.0A                                        |
| Voltage - Maximum              | 600V                                          |
| Material Info                  |                                               |
| Engineering Number             | MX-KE61-03                                    |
| Reference - Drawing Numbers    |                                               |
| Sales Drawing                  | 2016066163-000                                |

|                                                               |               |
|---------------------------------------------------------------|---------------|
| EU ELV                                                        |               |
| Not Relevant                                                  |               |
| EU RoHS                                                       | China RoHS    |
| Compliant                                                     |               |
| REACH SVHC                                                    |               |
| Not Contained Per - D(2021)4569-DC (8 July 2021)              |               |
| Halogen-Free                                                  |               |
| Status                                                        |               |
| Low-Halogen                                                   |               |
| For more information, please visit <a href="#">Contact US</a> |               |
| China ROHS                                                    | Green Image   |
| ELV                                                           | Not Relevant  |
| RoHS Phthalates                                               | Not Contained |

Search Parts in this Series  
201606 Series

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[201606-6163](#)