

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1120110006](#)
Status: **Active**
Overview: PC Network Interface Cards
Description: applicom PCU1500S7 Card, PROFIBUS (S7/MPI), 1 Channel, PCI 3.3/ 5V -OPC/DLL/ DAS - SCADA/HMI

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Literature \(PDF\)](#)

General

Product Family	Network Interface
Series	112011
Application	HMI, SCADA
Approvals	CE certified
Communication Speed	PROFIBUS 9.6 kbps to 1.5 Mbps
Mounting Style	PC Slot
Operating System	Windows7, Windows8/8.1, Windows Server 2003, Windows Server 2008, Windows Server 2012, Windows Vista

Overview	PC Network Interface Cards
Product Literature Order No	987651-3769
Product Name	applicom
Protocol	PROFIBUS
Protocol Detail	PROFIBUS FDL Send/Receive, PROFIBUS MPI Master, PROFIBUS S7 Client
Slot	Universal PCI 3.3V/5V
Software Downloads	APP-PS7-PCU
Type	PROFIBUS Card
UPC	78678894846
Woodhead	Yes

Physical

Channels	1
Interface	DAServer, DDE Server, DLL, OPC DA
Net Weight	140.000/g
Network Connection Type	PROFIBUS D-Sub Female (9 pin)
Packaging Type	Carton
Processor	AMD SC520
Temperature Range - Operating	0°C to +65°C

Electrical


Current - Maximum Input	5.5W
EMC	EN 61000-3-2, EN 61000-3-3, IEC 61000-6-2
Supply Voltage	3.3/5V

Material Info

Engineering Number	APP-PS7-PCU-C
--------------------	---------------

Reference - Drawing Numbers

Sales Drawing	SD-112011-0004-001
---------------	--------------------

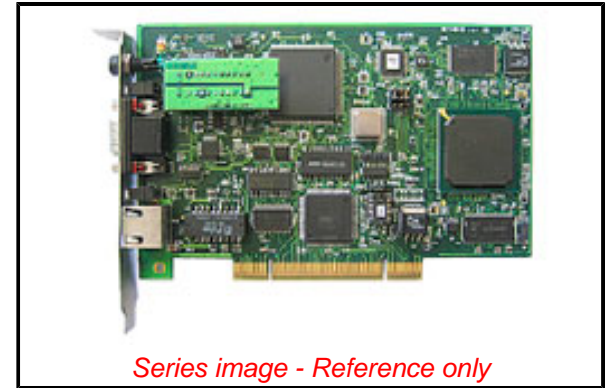

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per - ED/108/2014 (17 Dec 2014)

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[112011](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[112011-0006](#)