

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200651703

Status:


Active

Overview:

Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Single-Ended Cordset, 5 Poles, Female (90°) to Pigtail, 22 AWG, PVC Cable, 6.0m (19.68') Length

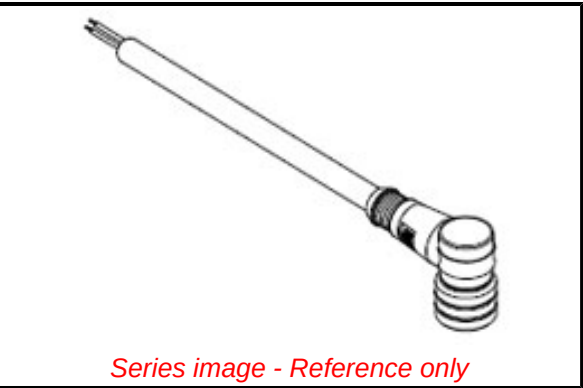

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	120065
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Protocol	N/A
Region	America
Type	Single Ended
UPC	78678850059
Physical	
Cable Diameter	5.72mm (.225")
Cable Length	6.0m (19.68')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Orientation	90° to Pigtail
Poles	5
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	22
Wire/Cable Type	E152210
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	805001A09M060
Reference - Drawing Numbers	
Sales Drawing	1200658471-000, SD-120065-027-001

EU ELV

Compliant with
Exemption 3

EU RoHS

Compliant with
Exemption 6(c)

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Lead

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

China RoHS

Not Relevant

Compliant with
Exemption 3

RoHS Phthalates

Not Contained

Search Parts in this Series

120065 Series

This document was generated on 01/18/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1200651703](#) [805001A09M060](#)