

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1203410607](#)
Status: **Active**
Overview: [Brad Industrial Ethernet Solutions](#)
Description: Standard RJ-45 CAT6A Double-Ended Cordset, 8 Poles, Male (Straight) to Male (Straight), 26 AWG, Shielded PUR Cable, 15.0m (49.21') Length

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-120341-600-001 \(PDF\)](#)


General	
Product Family	Industrial Cordsets
Series	120341
Connector End A	RJ-45 (standard)
Connector End B	RJ-45 (standard)
IP Rating	IP20
Material - Contact	Brass
Overview	Brad Industrial Ethernet Solutions
Performance Category	6A
Product Name	RJ45
Protocol	N/A
Region	America, Asia, Europe
Type	Double Ended
UPC	887191679082

Physical	
Cable Diameter	6.40mm (.252")
Cable Length	15.0m (49.21')
Color - Cable Jacket	Blue
Coupling Style	Threaded
Gender	Male-Male
Keyway	N/A
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	N/A
Material - Plating Mating	Gold
Net Weight	1666.000/g
Orientation	Straight to Straight
Poles	8
Temperature Range - Operating	-40°C to +70°C
Wire Size AWG	26
Wire/Cable Type	Shielded PUR

Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	48V

Material Info	
Engineering Number	E66E06020M150

Reference - Drawing Numbers	
Packaging Specification	PK-120341-600-001

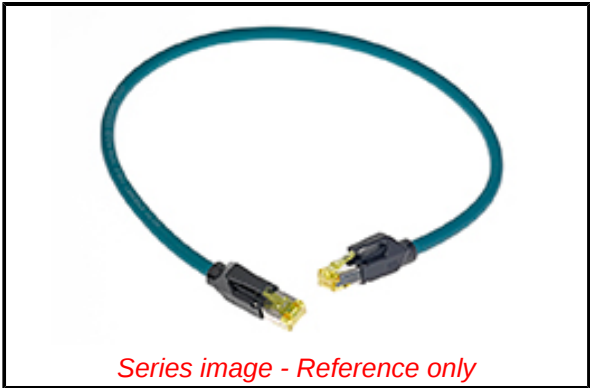

EU ELV Compliant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Not Relevant For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[120341](#) Series

Mates With
[120341](#) Micro-Change CAT6A Receptacles

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1203410607](#)