

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210360194](#)
Status: **Active**
Overview: mPm DIN Valve Connectors
Description: Micro-Change (M12) to Brad mPm DIN Form A - 18mm Cordset, 5 Poles, Male (Straight) to Male (90°), 1.50m (4.92') Length, 24V

Documents:
[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Industrial Cordsets
Series [121036](#)
Connector End A Brad mPm DIN A - 18mm
Connector End B Micro-Change (M12)
IP Rating IP65
Material - Contact Copper Alloy
Overview [mPm DIN Valve Connectors](#)
Product Name Micro-Change (M12), mPm
Protocol N/A
Region America, Europe
Type Double Ended
UPC 883906334789

Physical
Cable Diameter 5.72mm (.225")
Cable Length 1.50m (4.92')
Color - Cable Jacket Black
Coupling Style Threaded
Gender Male-Male
Keyway Single
LED Indicator No
Material - Cable Jacket PUR
Material - Connector Body Polypropylene
Material - Coupling Nut Nickel-plated Brass
Material - Plating Mating Gold
Net Weight 120.000/g
Orientation 90° to Straight
Poles 5
Temperature Range - Operating -25°C to +75°C
Wire Size AWG 20
Wire/Cable Type PUR

Electrical
Current - Maximum per Contact 4.0A
Voltage - Maximum 24V

Material Info
Engineering Number E850B0P12M015

Reference - Drawing Numbers
Sales Drawing SD-121036-001-001

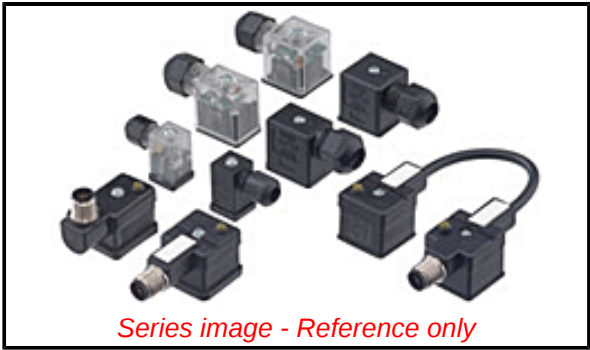

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)
Lead

**Halogen-Free
Status**

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[121036](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[121036-0194](#)