

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210360481](#)
Status: **Active**
Overview: [mPm DIN Valve Connectors](#)
Description: Micro-Change (M12) to Brad mPm DIN Form C - Micro 9.4mm Cordset, C4 Circuit, Yellow LED, 5 Poles, Male (Straight) to Male (90°), 1.50m (9.84') Length, 24V

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Industrial Cordsets
Series [121036](#)
Connector End A Brad mPm DIN C - Micro 9.4mm
Connector End B Micro-Change (M12)
IP Rating IP65
Material - Contact Copper Alloy
Overview [mPm DIN Valve Connectors](#)
Product Name Micro-Change (M12), mPm
Protocol N/A
Region America, Europe
Type Double Ended
UPC 883906502003

Physical
Cable Diameter 5.72mm (.225")
Cable Length 3.0m (9.84')
Color - Cable Jacket Black
Coupling Style Threaded
Gender Male-Male
Keyway Single
LED Indicator Yellow
Material - Cable Jacket PUR
Material - Connector Body Polypropylene
Material - Coupling Nut Nickel-plated Brass
Material - Plating Mating Gold
Net Weight 321.000/g
Orientation 90° to Straight
Poles 5
Temperature Range - Operating -25°C to +75°C
Wire Size AWG 20
Wire/Cable Type PUR

Electrical
Current - Maximum per Contact 1.5A
Voltage - Maximum 24V

Material Info
Engineering Number G850B0P12M030

Reference - Drawing Numbers
Sales Drawing 1210360510-000

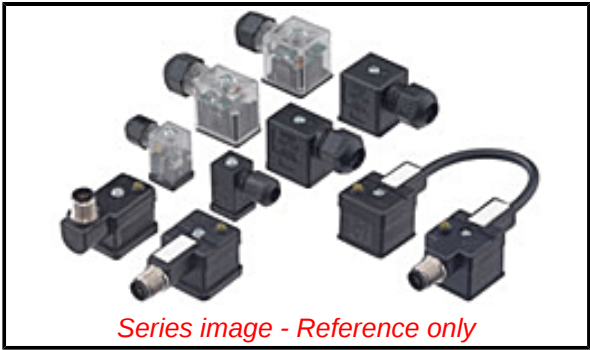

Series image - Reference only

EU ELV
Not Compliant

EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
Lead	
Halogen-Free Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[121036](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1210360481