

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300130515

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change A-Size Receptacle, 5 Poles, 7/8" - 1/2 NPT Threads, Male (Straight) to 16 AWG Leads, 0.305m (1.0') Length , US Auto Code, 16AWG, PVC

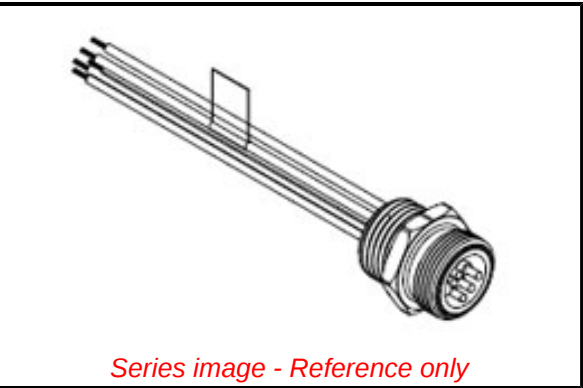

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Receptacles
Series	130013
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Type	Single Ended (pigtail)
UPC	78172553715
Physical	
Coupling Type	External Thread
Gender	Male
Keyway	Single
Length	0.305m
Material - Component	Zinc Die-Cast with Black Epoxy
Mounting Thread Size	1/2" - 14 NPT
Net Weight	165.880/g
Orientation	Straight
Panel Mount	Front
Poles	5
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	16
Wire/Cable Type	UL 1015, UL 1180
Electrical	
Current - Maximum per Contact	8.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	1R5006A24A120
Reference - Drawing Numbers	
Sales Drawing	SD-130013-024-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

130013 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1300130515](#) [1R5006A24A120](#)