

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300140037](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change B-Size Receptacle, 7 Poles, 1/2" - 14 NPT Threads, Female (Straight) to 16 AWG Leads, 0.305m (1.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
UL E152210

General

Product Family Industrial Receptacles
Series [130014](#)
Comments B-Size (1" - 16 UN-2A)
IP Rating IP67
NEMA Rating NEMA 6
Overview [Brad Mini-Change Connectors](#)
Product Name Mini-Change
Type Single Ended (pigtail)
UPC 78172553229

Physical

Coupling Type External Thread
Gender Female
Keyway Single
Length 0.305m
Material - Component Zinc Die-Cast with Black Epoxy
Mounting Thread Size 1/2" - 14 NPT
Net Weight 88.000/g
Orientation Straight
Panel Mount Front
Poles 7
Temperature Range - Operating -20° to +105°C
Wire Size AWG 16
Wire/Cable Type UL 1015

Electrical


Current - Maximum per Contact 8.0A
Voltage - Maximum 600V AC/DC

Material Info

Engineering Number 2R7004A20A120

Reference - Drawing Numbers

Sales Drawing SD-130014-006-001, SD-130014-009-001

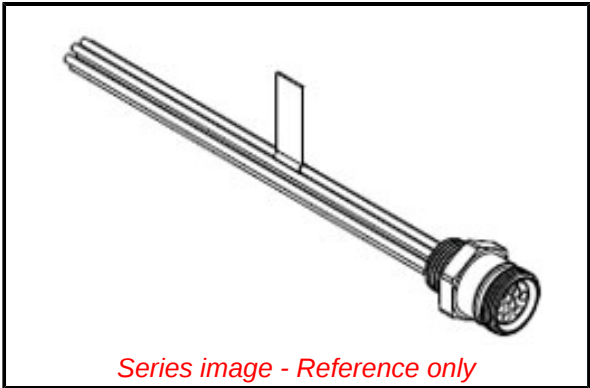

Series image - Reference only

EU ELV

Compliant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Lead

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Compliant

Not Contained

Search Parts in this Series

[130014](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1300140037](#) [2R7004A20A120](#)