

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0151661009

Status:


Active

Overview:

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:

0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 31.00mm Cable Length, Tin (Sn) Plating, 31 Circuits

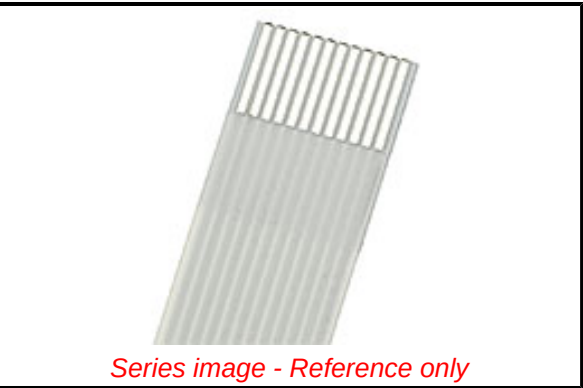

Series image - Reference only

Documents:

- [Drawing \(PDF\)](#)
- [Product Specification PS-15166-001-001 \(PDF\)](#)
- [Datasheet \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family

Series

Comments

Crimp Quality Equipment

Overview

Product Name

UPC

Cable

15166

Contacts on the same side, Type A

Yes

FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Premo-Flex FFC Jumper

884982923119

Physical

Cable Length

Circuits (Loaded)

Contact Layout Type

Material - Plating Mating

Net Weight

Packaging Type

Pitch - Mating Interface

Temperature Range - Operating

Wire Size AWG

Wire/Cable Type

31.00mm

31

A (same side)

Tin

1.000/g

Bag

0.50mm

-40° to +105°C

N/A

Flat Flex Cable

Electrical

Current - Maximum per Contact

Voltage - Maximum

0.5A

60V AC

Material Info

Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-15166-001-001

SD-15166-001-001

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS

ELV

RoHS Phthalates

Not Reviewed

Not Reviewed

Not Reviewed

Search Parts in this Series

15166 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15166-1009](#)