

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0309681101

Status:


Active

Overview:

H-DAC 64 Unsealed Connector System

Description:

2.54mm Pitch, 0.64mm Width H-DAC 64 High Density Automotive Crimp Housing, Dual Row, 10 Circuits, Polarization Option #2, Black

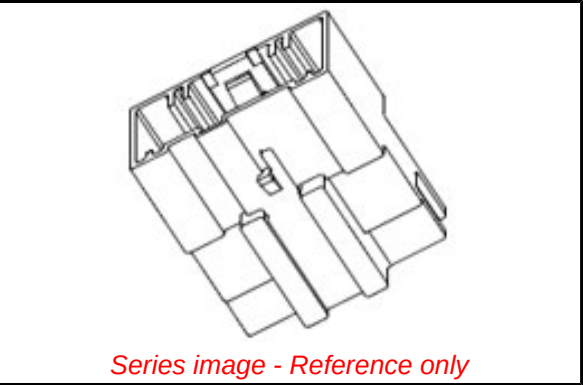

Documents:	
3D Model	Product Specification PS-30968-0001-001 (PDF)
3D Model (PDF)	Packaging Specification PK-30907-760-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	30968
Application	Automotive, Power, Wire-to-Wire
Comments	Polarization Option #2
Overview	H-DAC 64 Unsealed Connector System
Product Name	H-DAC 64
UPC	800754879750
Physical	
Circuits (maximum)	10
Color - Resin	Black
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Modified Polystyrene
Net Weight	5.130/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +100°C
Electrical	
Current - Maximum per Contact	7.0A
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-30907-760-001
Product Specification	PS-30968-0001-001
Sales Drawing	SD-30968-120-001

EU ELV Compliant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free Status Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
30968 Series

Mates With
30700 , 31389 H-DAC 64 High Density
Automotive Connectors

Use With
Contact Molex for Terminal information.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[30968-1101](#)