

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0391002505](#)  
**Status:** **Active**  
**Overview:** Eurostyle Two-Screw Barrier Strips  
**Description:** 15.00mm Pitch Beau Eurostyle Two-Screw Terminal Strips, 5 Circuits

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Terminal Blocks
Series	<a href="#">39100</a>
Application	Wire-to-Wire
Component Type	One Piece
Overview	<a href="#">Eurostyle Two-Screw Barrier Strips</a>
Product Name	Eurostyle Two Screw
Type	Barrier Strip
UPC	78172545261

**Physical**

Circuits (Loaded)	5
Circuits (maximum)	5
Color - Resin	White
Entry Angle	Horizontal
Lock to Mating Part	None
Material - Metal	Stainless Steel
Material - Resin	Nylon
Number of Rows	2
Orientation	Vertical
PCB Retention	Yes
Panel Mount	Mounting Holes Between Circuit
Pitch - Mating Interface	15.00mm
Pitch - Termination Interface	15.00mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	10, 12, 14, 6, 8

**Electrical**


Current - Maximum per Contact	63.0A
Voltage - Maximum	600V

**Material Info**

Engineering Number	M800-04-05-5-M1
--------------------	-----------------

**Reference - Drawing Numbers**

Sales Drawing	SD-39100-017-001
---------------	------------------

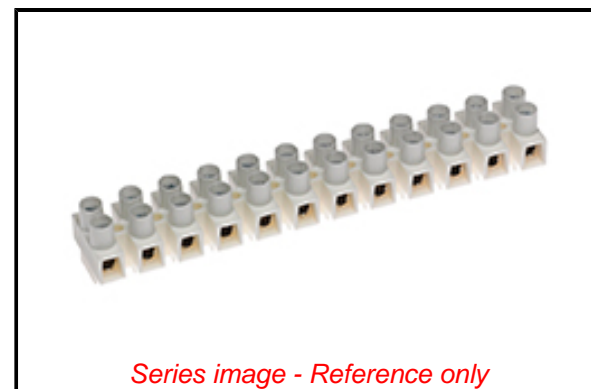

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per - ED/88/2018 (15 January 2019) lead

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

50 Image

Not Relevant

Not Contained

**Search Parts in this Series**

[39100 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39100-2505](#)