

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0533093071

Status:


Active

Overview:

SlimStack Board-to-Board/Board-to-FPC Connectors

Description:

SlimStack Board-to-Board Connector, 0.80mm Pitch, Plug, 5.65 or 6.65mm Mated Height, 30 Circuits, Right-Angle, with Boss

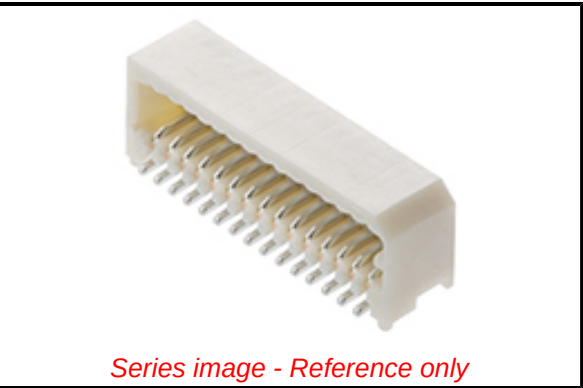

Series image - Reference only

- Documents:
- 3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-52465-014-001 (PDF)

Product Specification PS-52588-031-001 (PDF)

Product Specification PS-52588-032-001 (PDF)

Packaging Specification SPK-53309-001-001 (PDF)

Datasheet (PDF)

Product Guide (PDF)

RoHS Certificate of Compliance (PDF)

Reference Guide (PDF)

General	
Product Family	PCB Headers
Series	53309
Application	Board-to-Board, Signal
Overview	SlimStack Board-to-Board/Board-to-FPC Connectors
Product Name	SlimStack
Series Name	0.8 and above
UPC	822348191048
Physical	
Breakaway	No
Circuits (Loaded)	30
Circuits (maximum)	30
Color - Resin	Natural
Durability (mating cycles max)	30
First Mate / Last Break	No
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Mated Height	5.65mm
Mated Width	4.70mm, 7.20mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	574.175/mg
Number of Rows	2
Orientation	Right Angle
PC Tail Length	0.40mm
PCB Locator	No
PCB Retention	None
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.80mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Polarized to PCB	No
Shrouded	Fully
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	0.5A

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series
53309 Series

Mates With
Board-to-Board Receptacle 52465 , 52588

Voltage - Maximum	50V AC (RMS)/DC
Material Info	
Reference - Drawing Numbers	
Packaging Specification	SPK-53309-001-001
Product Specification	PS-52465-014-001, PS-52588-031-001, PS-52588-032-001
Sales Drawing	533090000-001, 533091000-001

This document was generated on 09/13/2021
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

53309-3071