

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0901420044](#)
Status: **Active**
Overview: [C-Grid III Interconnects](#)
Description: 2.54mm Pitch C-Grid III Crimp Housing Dual Row, 44 Circuits, Black

Documents:

3D Model	Product Specification PS-99020-0001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
3D Model (PDF)	

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	90142
Application	Signal, Wire-to-Board
Overview	C-Grid III Interconnects
Product Name	C-Grid III
UPC	800753656123


Physical

Breakaway	No
Circuits (maximum)	44
Color - Resin	Black
Flammability	94V-1
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	PPO
Net Weight	2.984/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Pitch - Termination Interface	2.54mm
Polarized to Mating Part	Yes
Ports	0
Stackable	No
Temperature Range - Operating	-55° to +105°C

Material Info

Reference - Drawing Numbers

Product Specification	PS-99020-0001-001
Sales Drawing	SD-90142-001

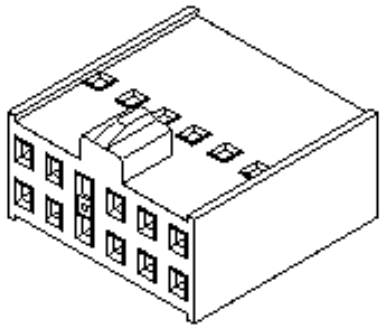

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[90142](#) Series

Mates With

C-Grid III Header, Dual Row [90122](#) , [90130](#) ,
[90131](#)

Use With

C-Grid III Crimp Terminal [90119](#)
 C-
Grid III Pre-Crimped Lead [797582022](#) ,
[797582023](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[90142-0044](#)